
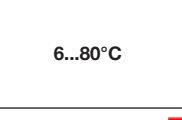




Ball Valves.

6-way Electronic Pressure-independent Control Valves – internal thread



		Running times	(Control) Operating range	MP-Bus® BACnet IP BACnet MS/TP	LR..
DN 15	AC/DC 24 V	90 s	DC (0) 2...10 V	Yes	
DN 20	AC/DC 24 V	90 s	DC (0) 2...10 V	Yes	
Internal thread Rp ISO 7/1	PN 16 $T_{max} = 100^{\circ}\text{C}$				
6-way	DN [mm]	V_{nom} [l/h]	V_{max} low-noise [l/h]		Δp_s [kPa]
EP015R-R6+BAC 	15	1260	840		
EP020R-R6+BAC 	20	2340	1620		Δp_{max} [kPa]
					350
					100