

**Certified,
maintenance-free
and future-proof.**

The new generation of motorised potable water valves

The new generation of potable water valves from Belimo combine certified 2-way ball valves with compact actuators, fail-safe and non fail-safe. A compact and maintenance-free unit, for long and worry-free operation.

Benefit from the many advantages:

- Certified for application in potable water installations
- Future-proof thanks to the use of contemporary, dezincification-free materials
- Maintenance-free use thanks to resistance against soiling and deposits
- Simple and versatile motorisation using tried-and-tested standard actuators from Belimo
- Great price-performance ratio

Certified and future-proof.




Open/close ball valve

- Suitable for drinking water temperatures of 5...100°C
- For high nominal pressures (PN40)
- Maintenance-free, durable and air-bubble tight
- Resistant against soiling and limescale deposits
- Future-proof thanks to contemporary materialisation (DZR/CR standard)
- Certified for application in potable water installations



Energy-saving motorisation with standard rotary actuators

- Compact, strong and reliable
- Simple and versatile motorisation using tried-and-tested standard actuators from Belimo
- Fail-safe and non fail-safe (spring return) or fast running actuators
- Great price-performance ratio

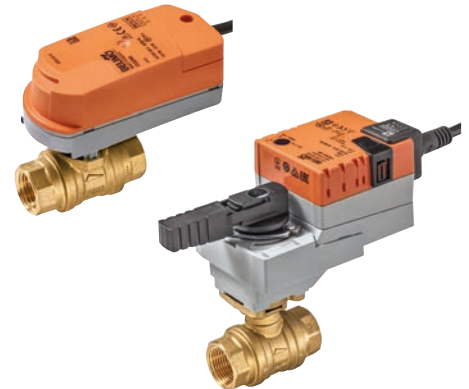

New: Motorisation of the DN15 valves is now also possible with the space-saving CQ actuator series.



For use throughout Europe thanks to broad certification

Belimo has placed particular emphasis on future-proofing in the new development of these potable water valves. Thanks to the selection of modern materials, these new potable water valves are DZR/CR-certified (dezincification-free). Since this topic is addressed by more and more standards, you will be one step ahead with our valves.

CERTIFICATION

Belimo's potable water valves have the following approvals: ACS, DVGW, KIWA, KIWA Sweden, ÜA and WRAS.

Valve product range	Motorisation							
	Type	DN	PN	Rp ["]	kvs [m³/h]	CQ..	LR..	NR..
C215QPW-N	15	40	1/2	16	■	-	-	-
R215PW-N	15		1/2	16	-	■	-	-
R220PW-P	20		3/4	32	-	■	-	-
R225PW-Q	25		1	40	-	■	-	-
R232PW-Q	32	25	1 1/4	63	-	-	■	-
R240PW-R	40		1 1/2	100	-	-	-	■
R250PW-S	50		2	150	-	-	-	■

BELIMO Automation AG

Brunnenbachstrasse 1, 8340 Hinwil, Switzerland
+41 43 843 61 11, info@belimo.ch, www.belimo.com

