









TRD24-SR (-T)  
TR24-SR (-T)  
TRY24-SR

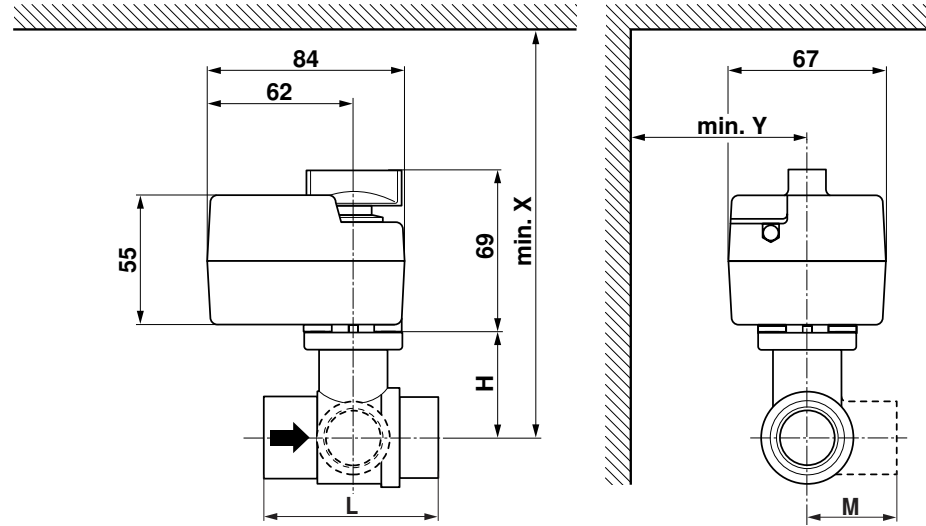

70632-00001.C

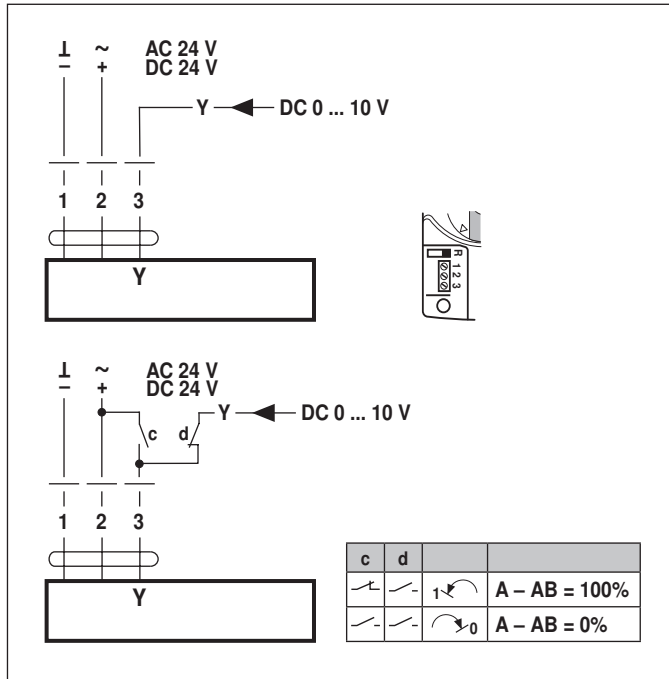

		°C	DN		Rp	G	PN	mm			TRD24-SR(-T)		TR(Y)24-SR(-T)	
			max.	mm				"	"	"	L	H	M	X
R2..K	R3..K	100	10	3/8	3/8			52	35	28	174	75		
R4..K	R5..K	100	10	3/8		3/4		69	31.5	34	171	75		
R2..	R3..	100	15	1/2	1/2			67	45	39			184	75
R4..	R5..	100	15	1/2		1		74	44	38			183	75
R6..R	R7..R	100	15	1/2			6	101.5	45	73			184	80
R4..DK		130	10	3/8		3/4		65	38	13			177	75

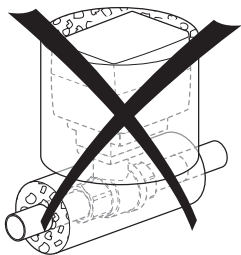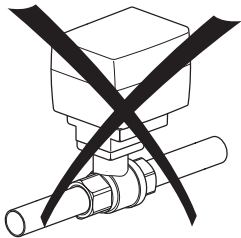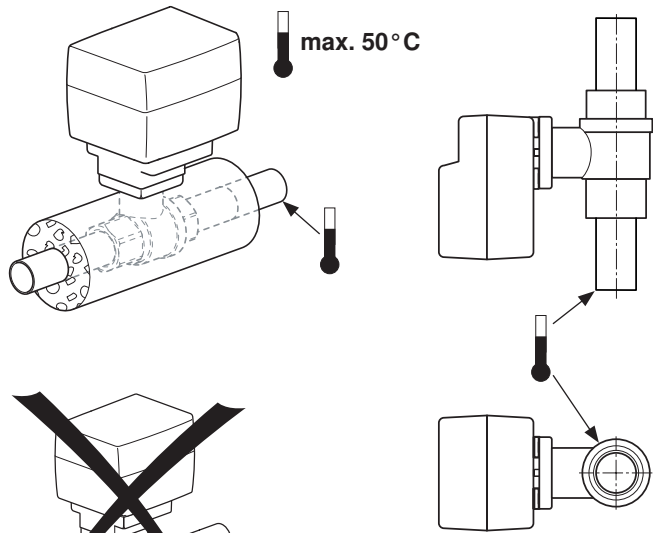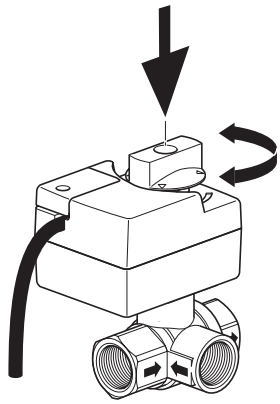

	R2..K	R3..K	max. 100 °C
	R4..K	R5..K	max. 100 °C
	R2..	R3..	max. 100 °C
	R4..	R5..	max. 100 °C
	R6..R	R7..R	max. 100 °C
	R4..DK		max. 130 °C

