


Shaft extension AV8-25


- Length approx. 250 mm
- For damper spindles $\varnothing$ 10 ... 25 mm
- $\varnothing$ Extension 20 mm

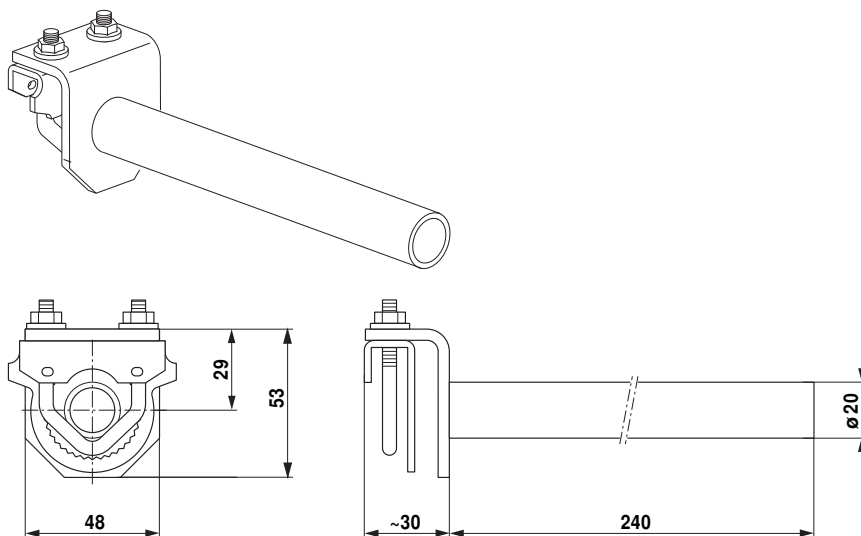

For utilisation with stainless CrNi (INOX) rotary axes, the use of the accessory AV12-25-I is recommended: $\varnothing$ 12 ... 25 mm

Shaft extension AV12-25-I


- Length approx. 250 mm
- For damper spindles CrNi (INOX)
 $\varnothing$ 12 ... 25 mm
- $\varnothing$ Extension 20 mm

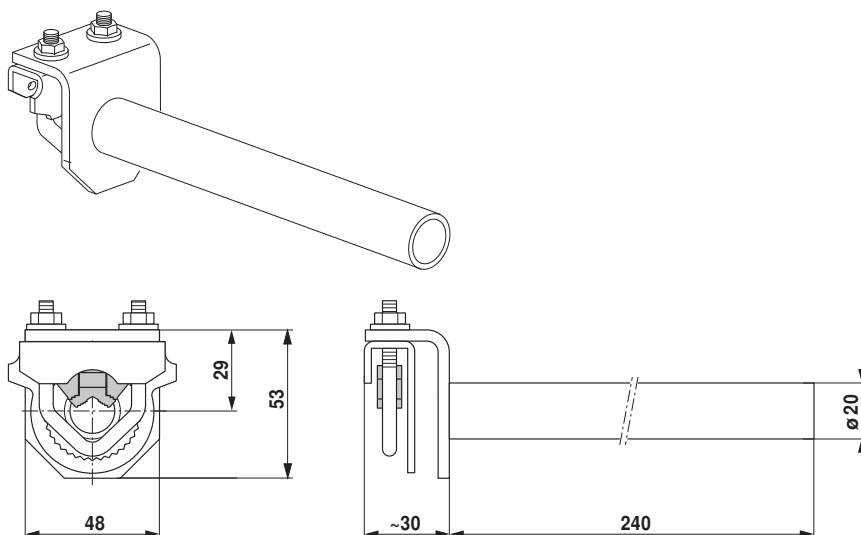
Single side spindle clamp K-ENSA


- For damper spindle $\varnothing$ 10 ... 26 mm

Packaging unit: 20 pieces

For utilisation with stainless CrNi (INOX) rotary axes, the use of the accessory K-ENSA-I is recommended: $\varnothing$ 12 ... 26 mm

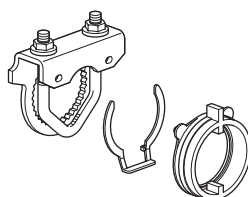
Single side spindle clamp K-ENSA-I


- For damper spindle CrNi (INOX)
 $\varnothing$ 12 ... 26 mm

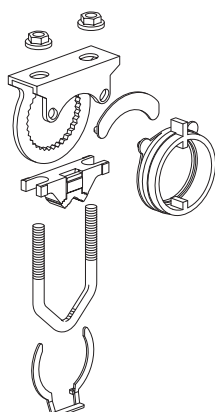

Packaging unit: 20 pieces

Reversible spindle clamp K-SA


- For damper spindles $\varnothing$ 10 ... 20 mm
- For damper spindles CrNi (INOX)
 $\varnothing$ 12 ... 20 mm

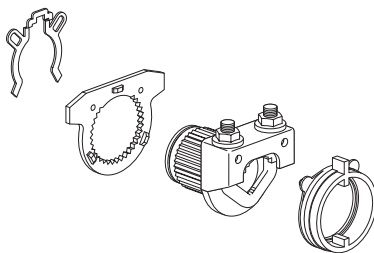

Packaging unit: 20 pieces

Form-fit adapters ZF..-NSA


Article number	Shaft dimensions
• ZF10-NSA	10 x 10 mm
• ZF12-NSA	12 x 12 mm
• ZF16-NSA	16 x 16 mm

 

Packaging unit: 20 pieces


Damper crank arm KH8

- For single side spindle clamp K-ENSA(-I)
- For damper spindles
- Galvanized steel
- Clamping range $\varnothing$ 10 ... 18 mm
- Slot width 8.2 mm

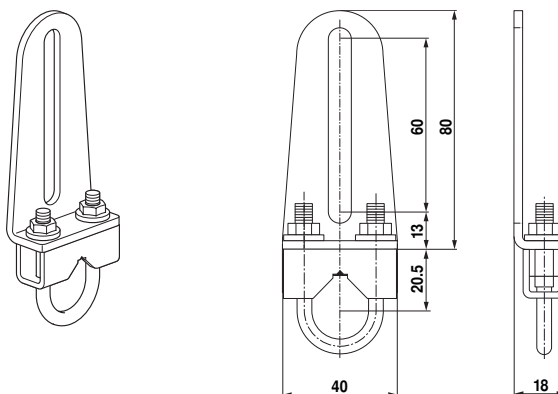


Actuator crank arm AH-20

- For standard spindle clamp (reversible)
K-SA
- Slot width 8.2 mm
- Galvanized steel

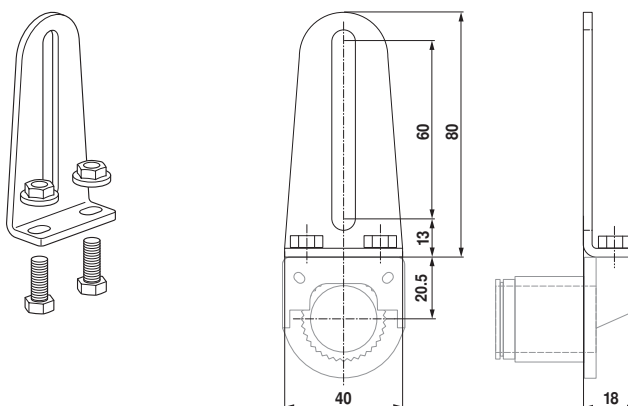



Actuator crank arm AH-25

- For single side spindle clamp K-ENSA(-I)
- Slot width 8.2 mm
- Galvanized steel



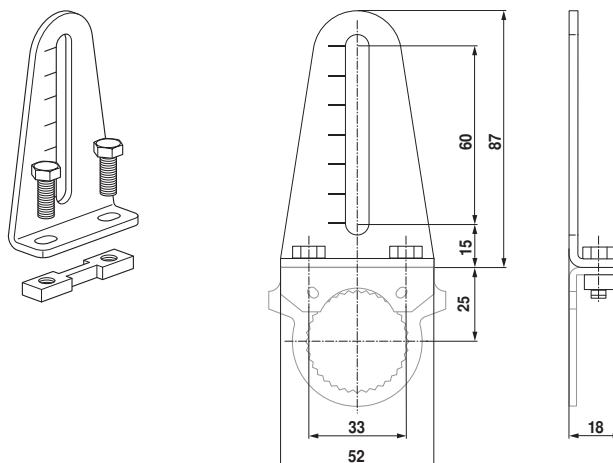


Mounting kit for damper linkage ZG-SMA

- For flat mounting


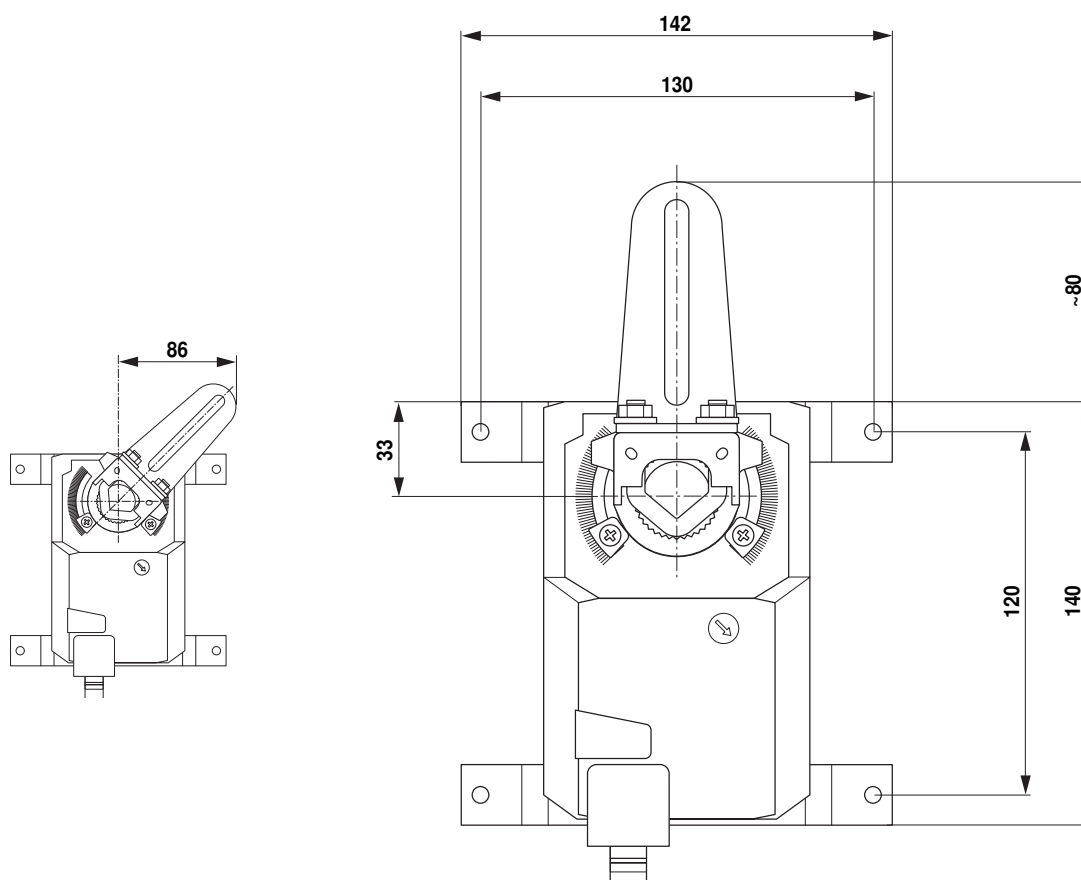
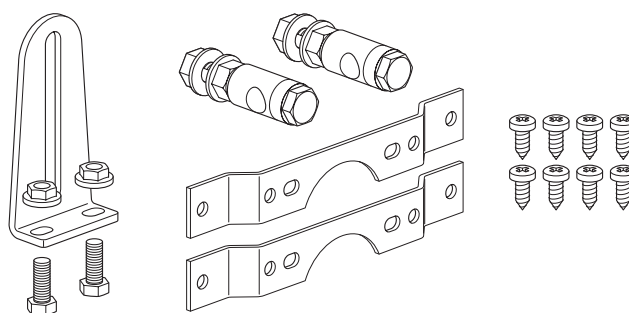


Anti-rotation strap Z-ARS180

 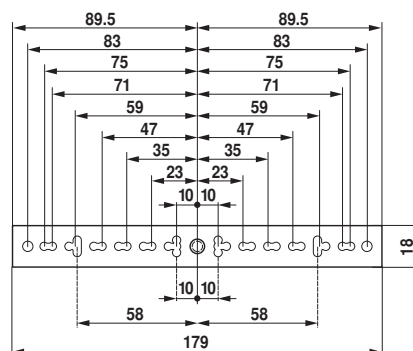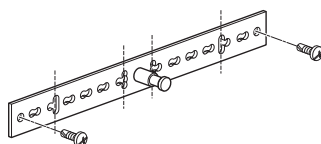

Packaging unit: 20 pieces

 

Anti-rotation strap Z-ARS230

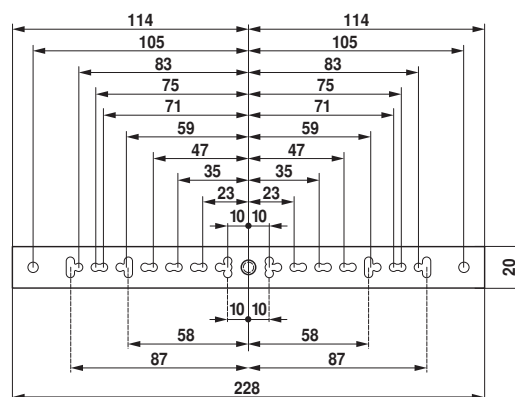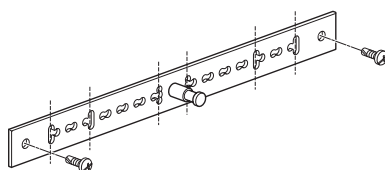

Packaging unit: 20 pieces



Ball joint KG10A

 - Suitable for KH8 damper crank arms
- For round steel rod with $\varnothing$ 10 mm
- Galvanized steel

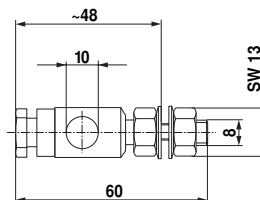

Ball joint KG8

 - Suitable for KH8 damper crank arms
- For round steel rod with $\varnothing$ 8 mm
- Galvanized steel

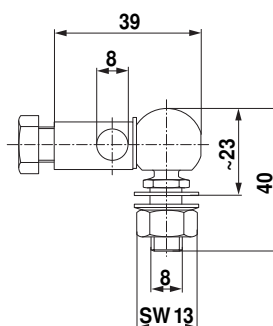

Position indication Z-PI



Packaging unit: 20 pieces