








BELIMO

AV24-3
AV230-3

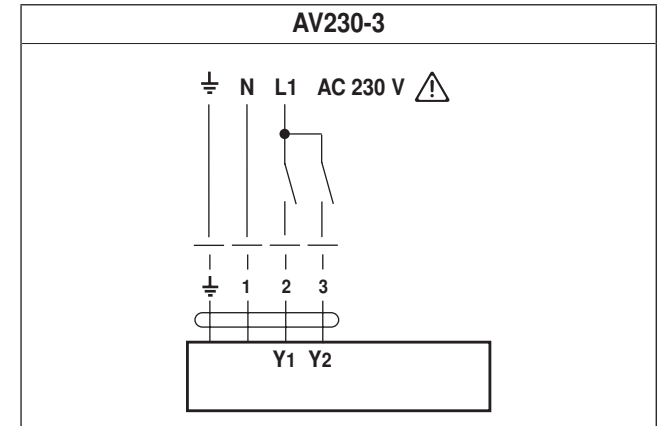

70771-00001.B



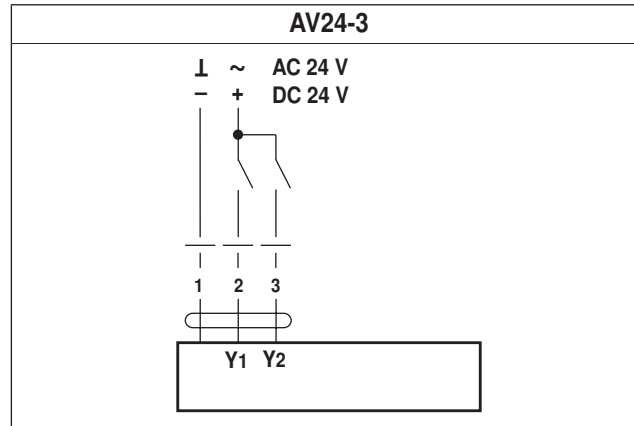


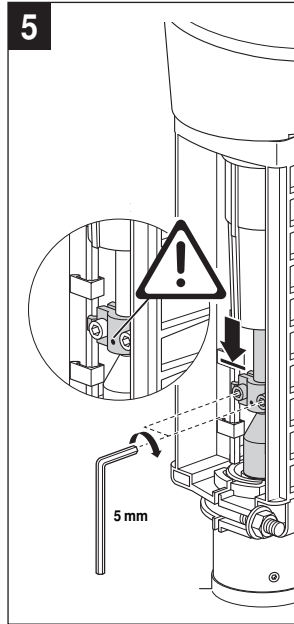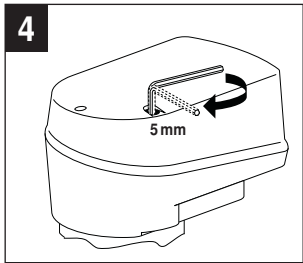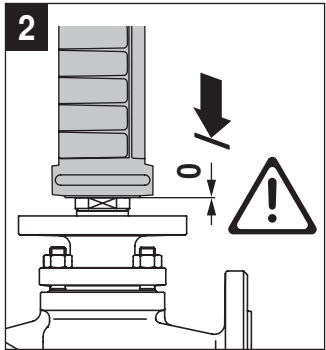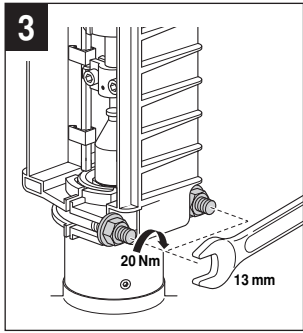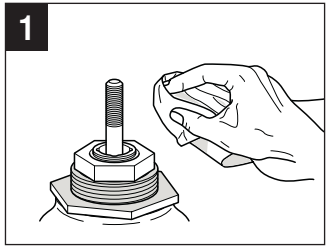

6

S1.1	Symbol
	7.5 s/mm →
	3.75 s/mm →
S1.2	Symbol
	▲ H6/7..N H6/7..R H7..X..S2 H7..Y..S2
	▼ H6..S H6..SP H6..X..S(P)2

⚠

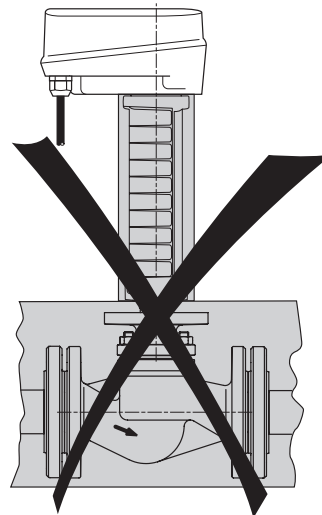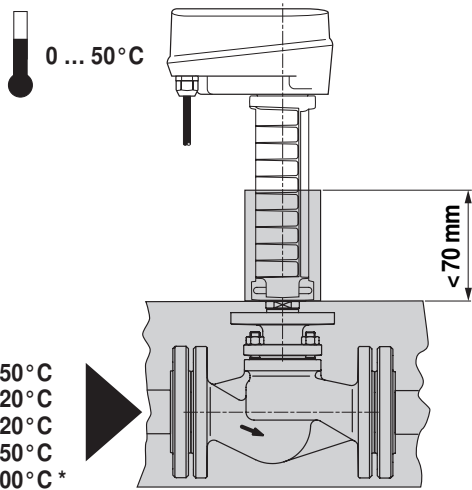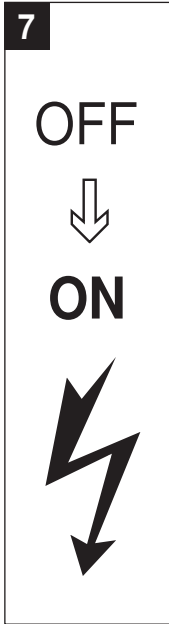

- H6..S / H6..SP max. 150 °C
- H6..N / H7..N max. 120 °C
- H6..R / H7..R max. 120 °C
- H6..X..S2 max. 150 °C
- H7..X..S2 max. 200 °C *
- H7..Y..S2 max. 200 °C *

