

**BELIMO**








**NV(D)230-3  
NV24-3**



**NV230-3-R  
NV24-3-R**

70340-00001.A

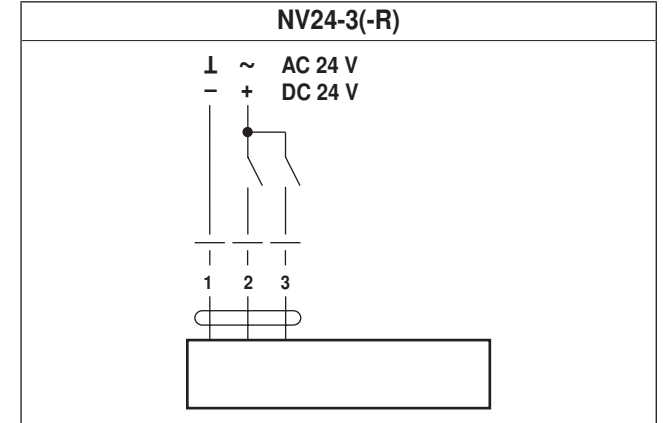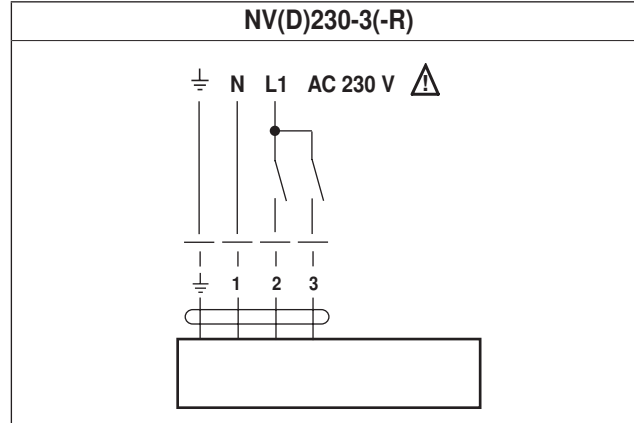


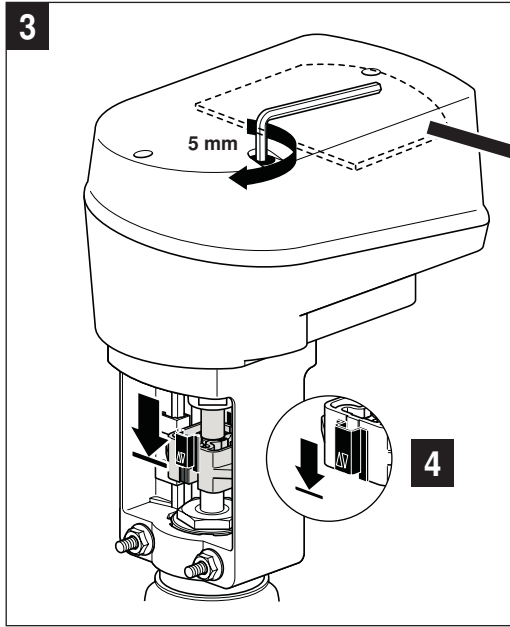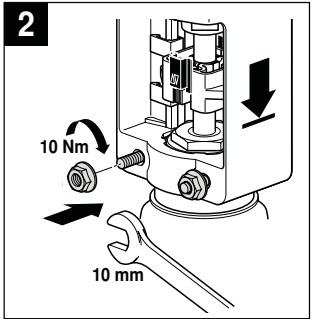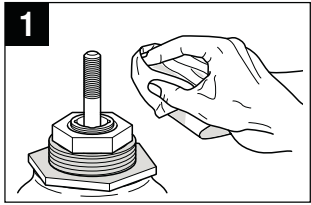

**5**

S1.1	Symbol
	7.5 s/mm
	3.75 s/mm
S1.2	Symbol
	H4/5..B H6/7..N H6/7..R H7..X..S2 H7..Y..S2
	H6..S H6..SP H6..X..S(P)2

⚠

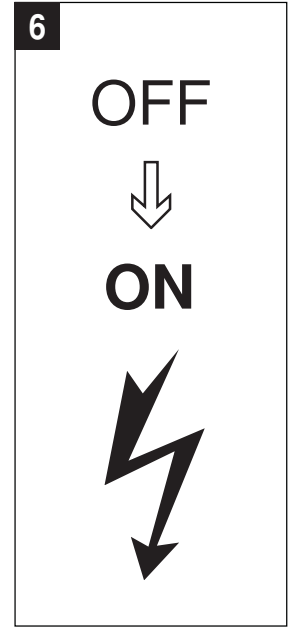

0...50°C

< 30 mm

	H6..S / H6..SP	max. 150°C
	H4..B / H5..B	max. 120°C
	H6..N / H7..N	max. 120°C
	H6..R / H7..R	max. 120°C
	H6..X..S2	max. 150°C
	H7..X..S2	max. 200°C *
	H7..Y..S2	max. 200°C *

