


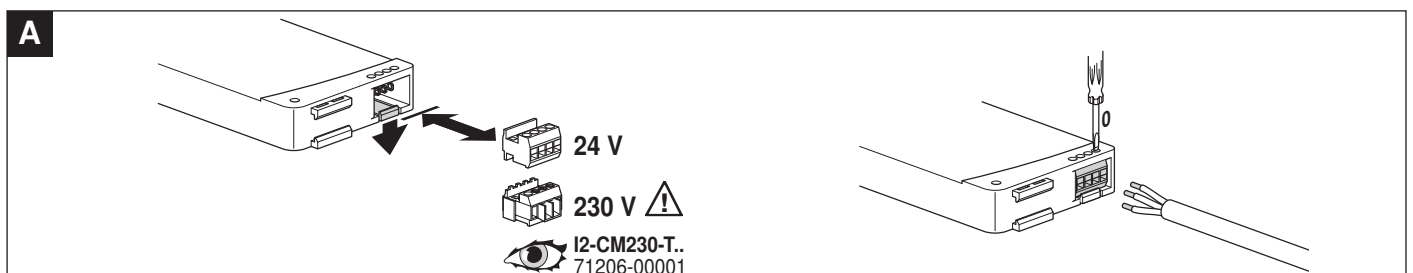
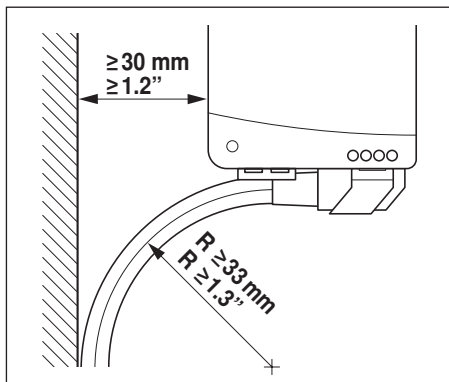
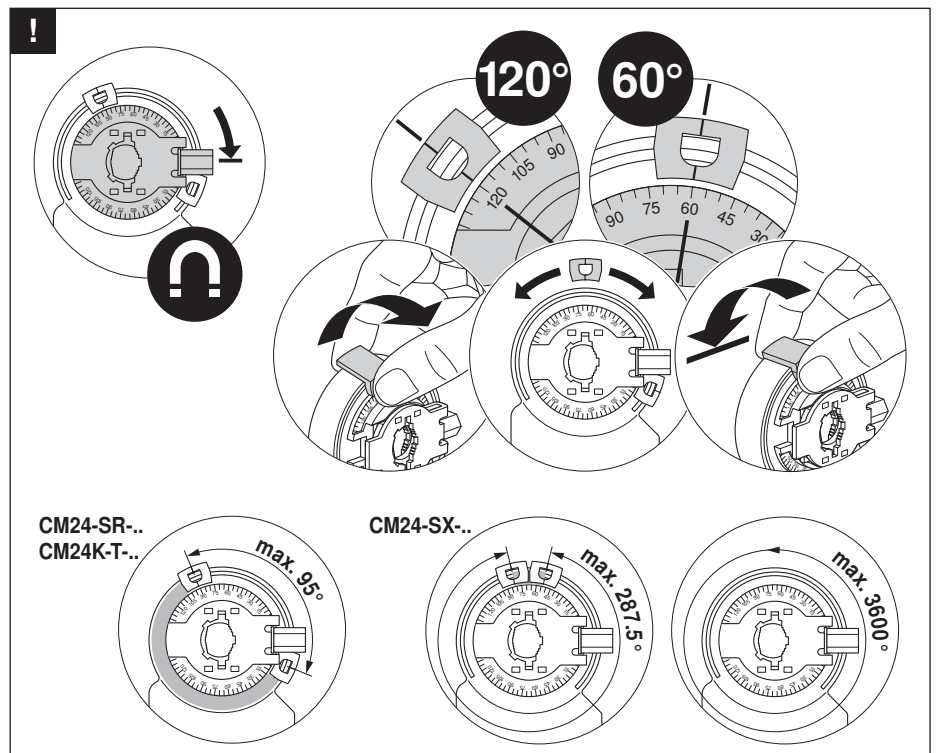
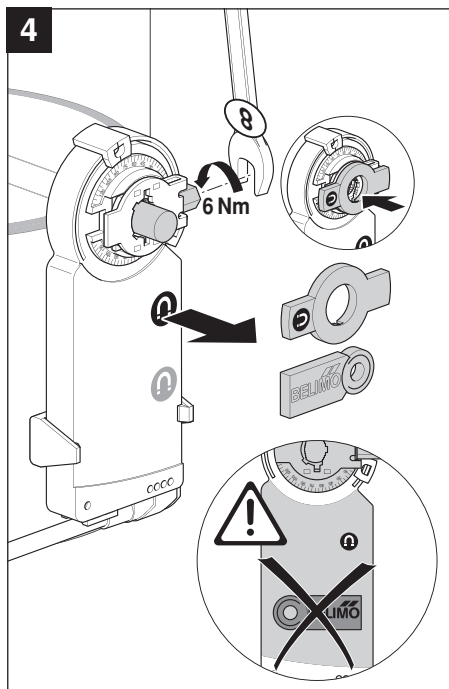
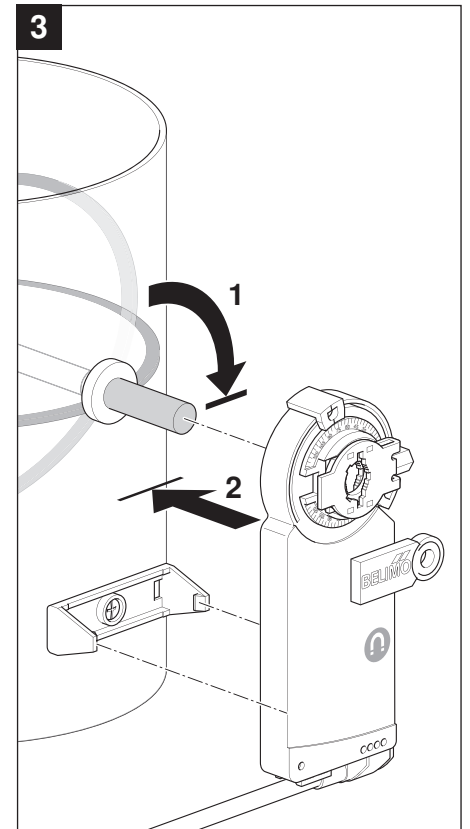
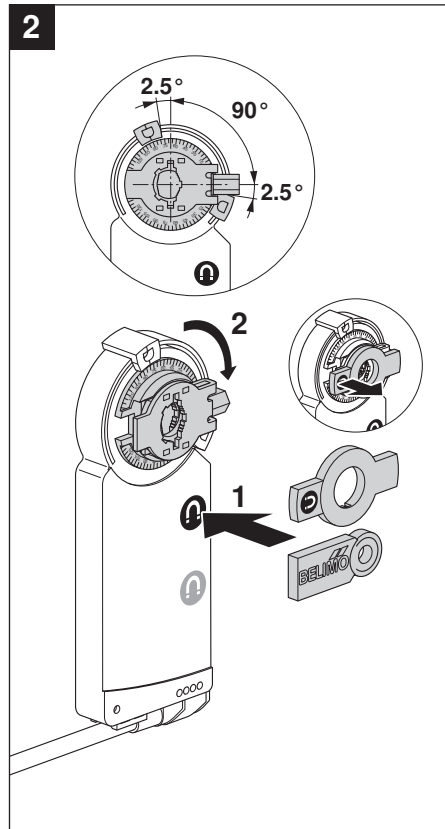
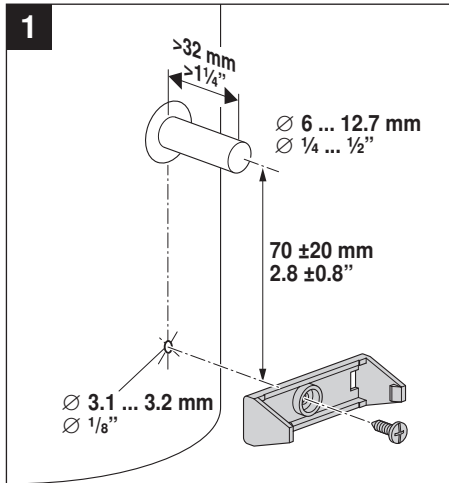
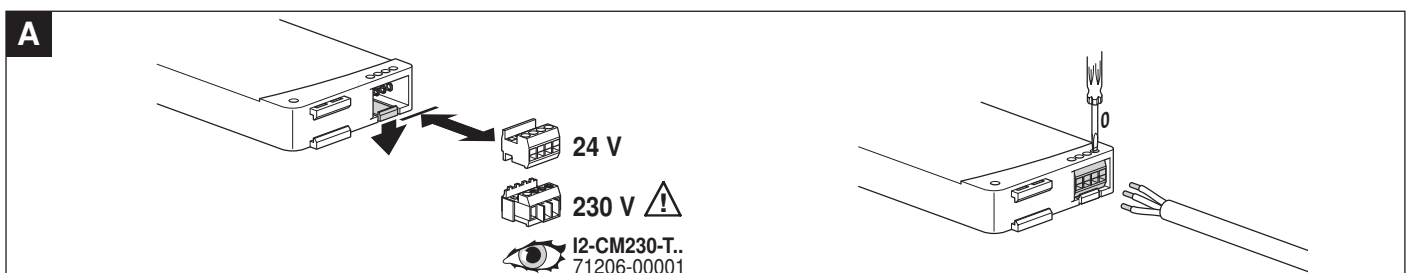
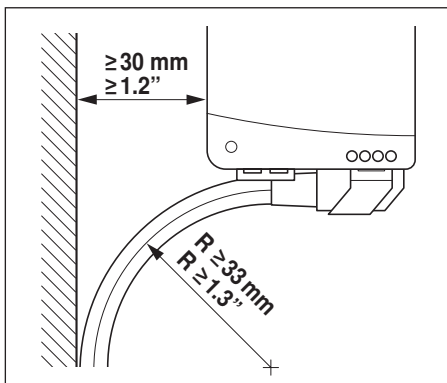
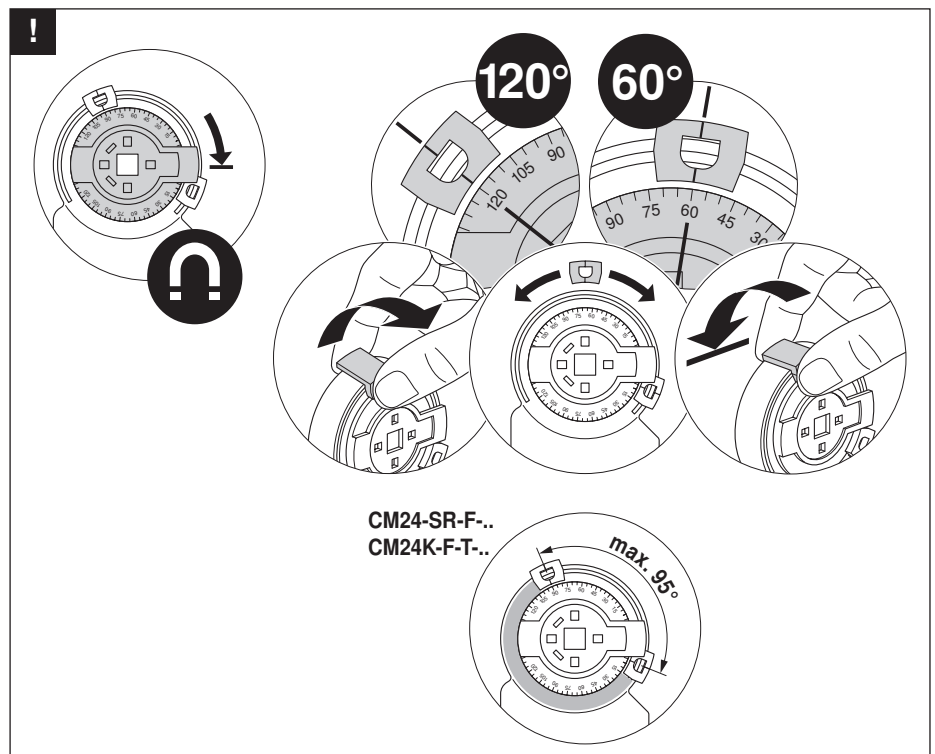
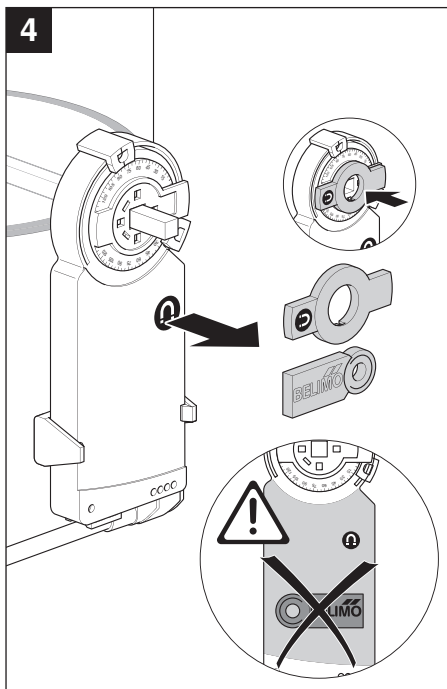
 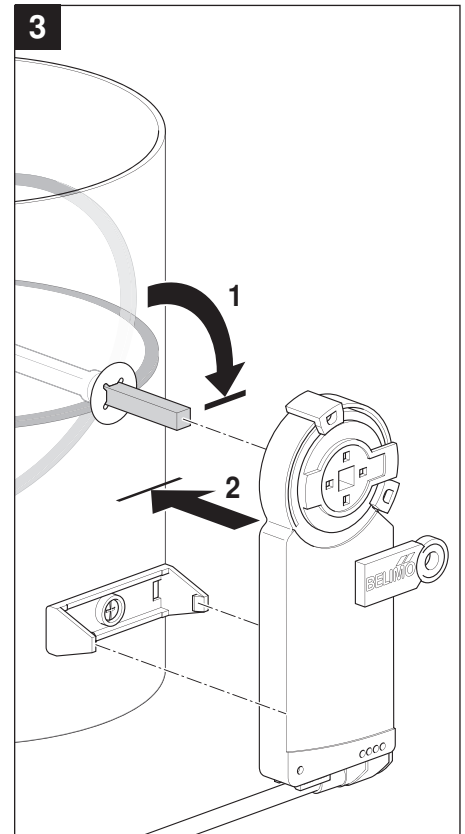


CM24-.. / CM24-T-.. / CM230-.. / CM24-SR-.. / CM24-SR-T-.. / CM24K-T-.. / CM24-SX-..


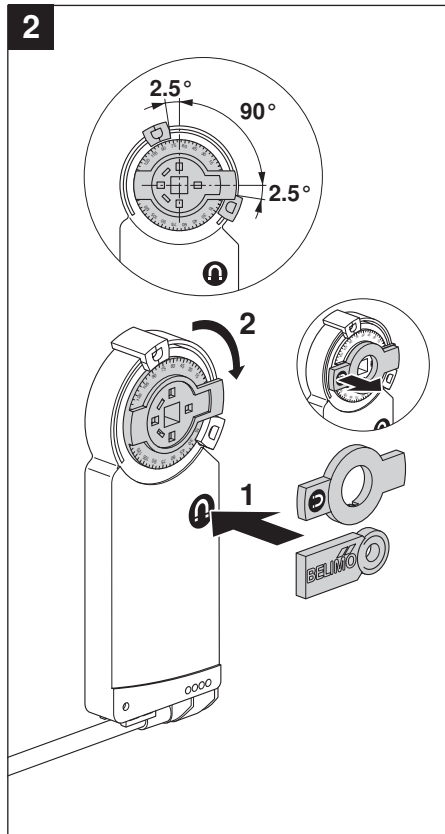


CM24-F.. / CM24-F-T.. / CM230-F.. / CM24-SR-F.. / CM24-SR-F-T.. / CM24K-F-T..

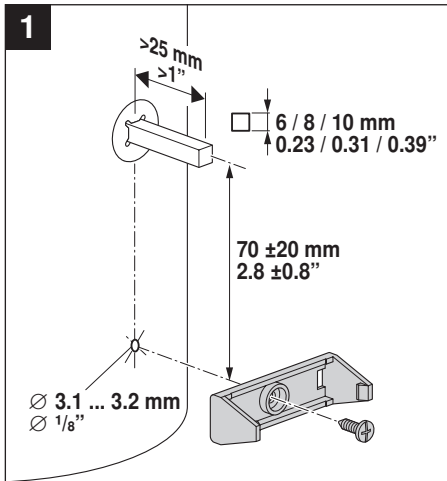







AC 24 V / DC 24 V

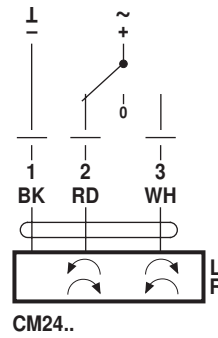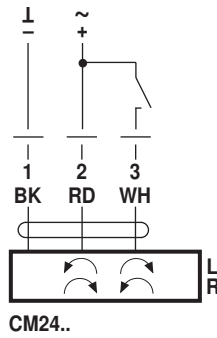

DC 24 V  
(SKM230..)

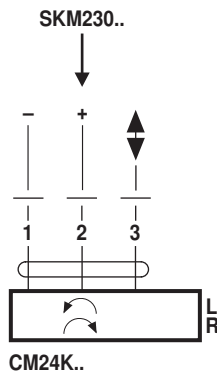

AC 100 ... 240 V ⚠

 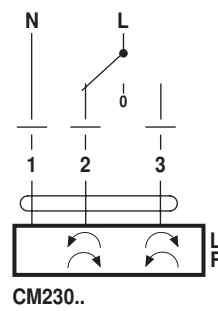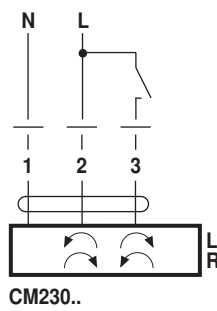

AC 24 V / DC 24 V

