





FRU230-3(-T)

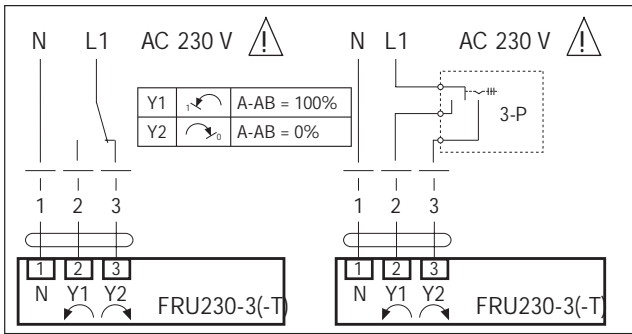

AC 230 V



www.belimo.com

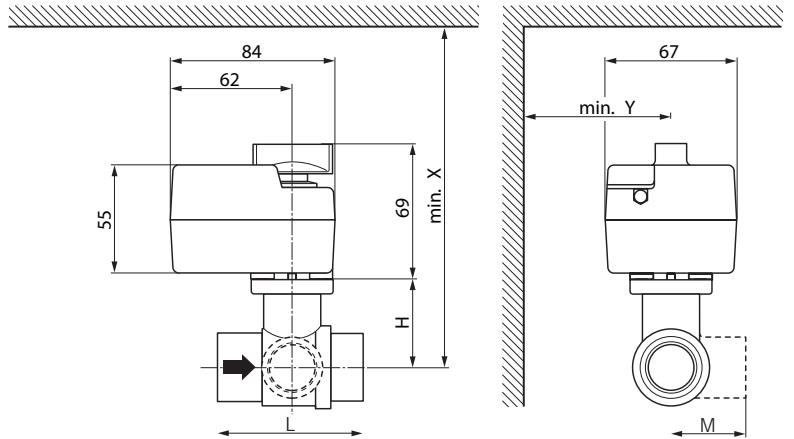

↔	↔	DN		Rp	mm					
		mm	"	"	L	H	M	X	Y	
										FRU230-3
	RB215	RB315	15	1/2	1/2	70.5	44	33	184	75
	RB220	RB320	20	3/4	3/4	73	44	33	183	75
	RB225	RB325	25	1	1	92	45	46	184	80

