




FRU24

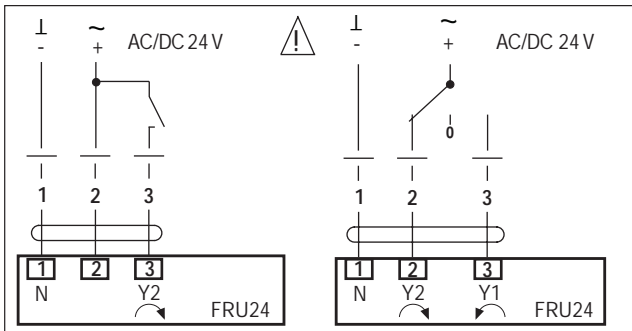


AC/DC 24 V

Y2 A - AB = 0%



www.belimo.com

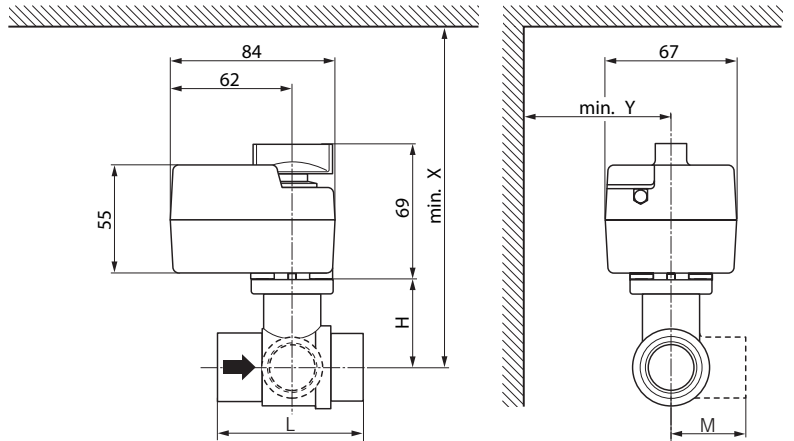

↔	↻	DN		mm				
		mm	"	L	H	M	FRU24	
							X	Y
RB215	RB315	15	1/2	70.5	44	33	184	75
RB220	RB320	20	3/4	73	44	33	183	75
RB225	RB325	25	1	92	45	46	184	80

