
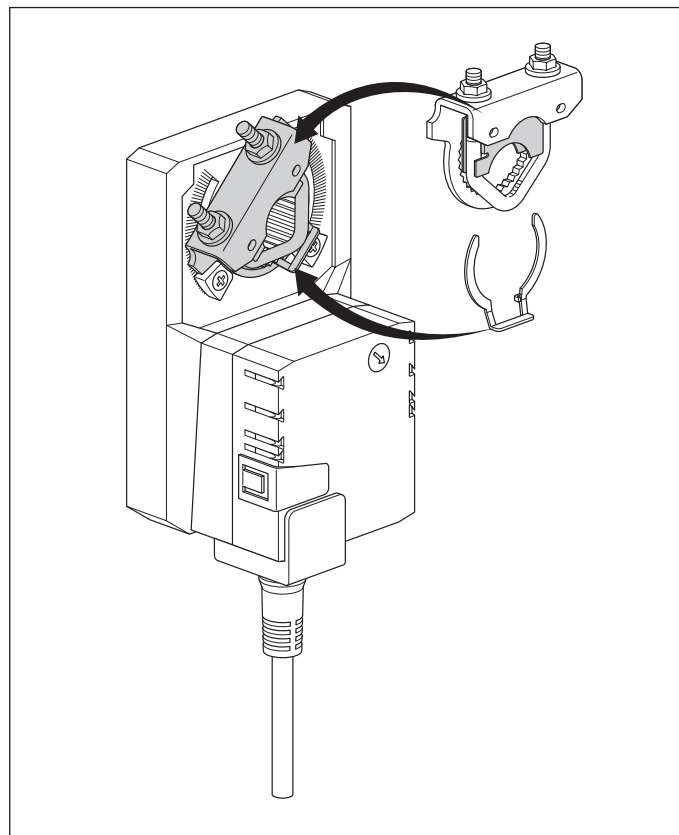
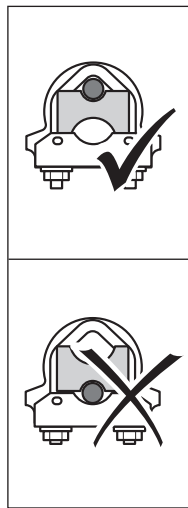
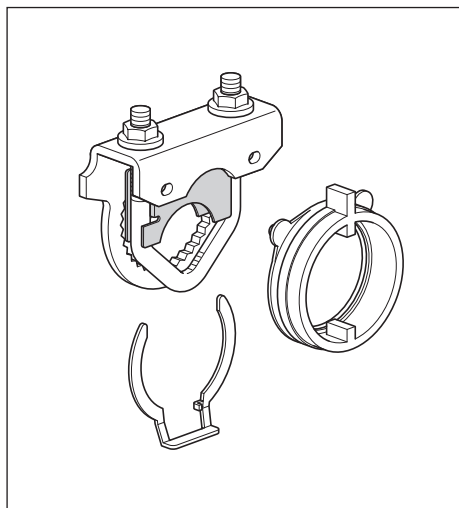
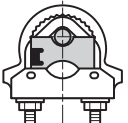
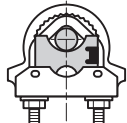


70684-00001.C

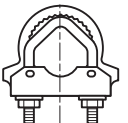

		
∅ ≥10.0 mm	∅ ≥16.0 mm	∅ ≥8.0 mm
⊕ 12.7 mm 1/2"	⊕ 19.0 mm 3/4"	⊕ 25.4 mm 1"
∅ ≤18.0 mm	∅ ≤22.0 mm	∅ ≤26.7 mm