

1

	8 ... 26.7	≥ 8	≤ 26.7	NM..A..
	10 ... 20	≥ 10	≤ 20	NMD230A
CrNi (INOX)	12 ... 20	≥ 10	≤ 20	NMD230A


2



3

4


5

NMD230A

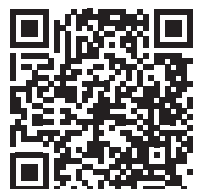


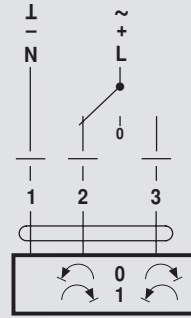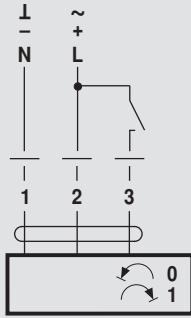


AC 24 V / DC 24 V
DC 48 ... 110 V
(NM72A..)

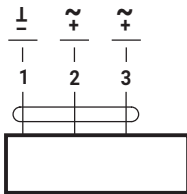

NM24A..
NM72A..

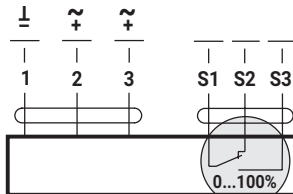


NM24A-S..

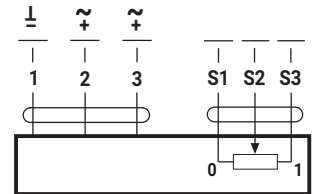


NM24AP5..



AC 100 ... 240 V

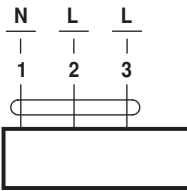


NM230A..
NMD230A

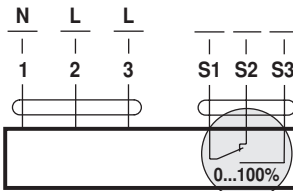


NM230A-S..

 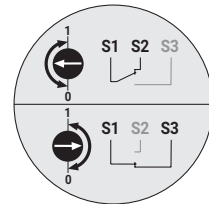

AC 24 V / DC 24 V

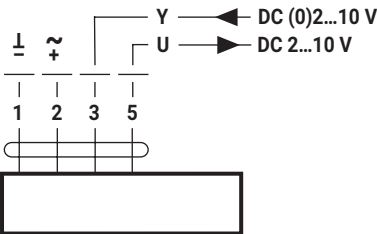


NM24A-SR..
NM24A-MF..

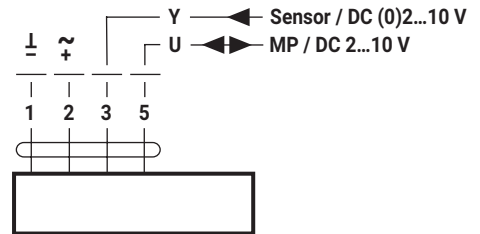


NM24A-MP..

DC 48 ... 110 V
(NM72A-SR..)

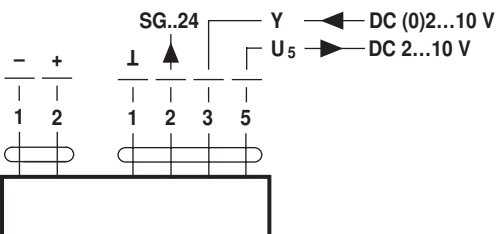


NM72A-SR..

AC 100 ... 240 V

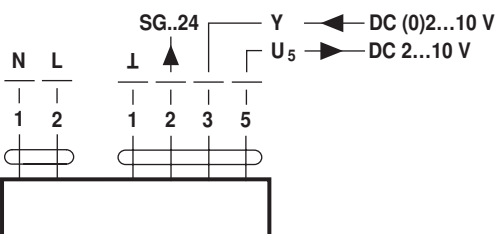

NM230ASR..

AC 24 V / DC 24 V
(NM24A-V / VR..)

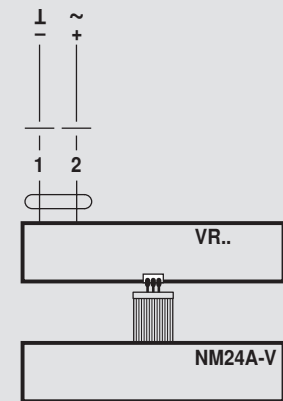

NM24A-V / VR..