





Picture may differ from product

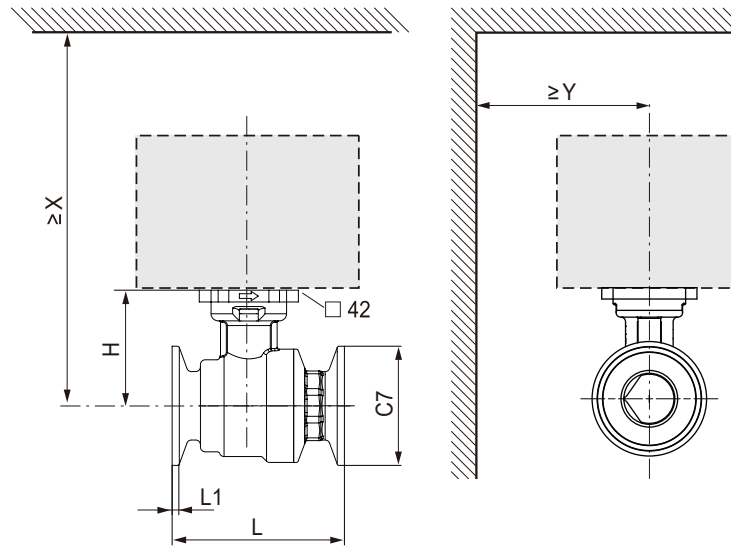

72207-00001.C

t -18 ... +100°C	Dimensions [mm]																	
PN 16	DN		mm				LR..A		NR..A		SR..A		LRF ..		NRF ..A		SRF..A	
	mm	L	H	C7	L1	X	Y	X	Y	X	Y	X	Y	X	Y	X	Y	
R8015S..	15	68	34.5	Φ34	2.85	190	75					195	90					
R8020S..	20	68	40.5	Φ34	2.85	196	75					201	90					
R8025S..	25	73	49	Φ50.5	2.85	205	75					210	90					
R8032S..	32	76	47.5	Φ50.5	2.85	203	75							233	90			
R8040S..	40	90	57	Φ50.5	2.85			248	80					238	90			
R8050S..	50	94	61	Φ64	2.85			254	80	252	80			243	90	242	90	
R8065S..	65	130	90	Φ77.5	2.85					286	80					276	90	
R8080S..	80	152	97.5	Φ91	2.85					293	80					283	90	

