

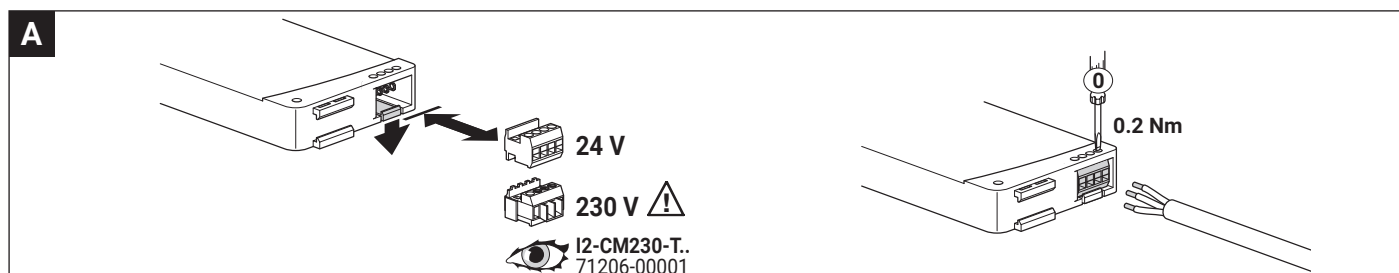
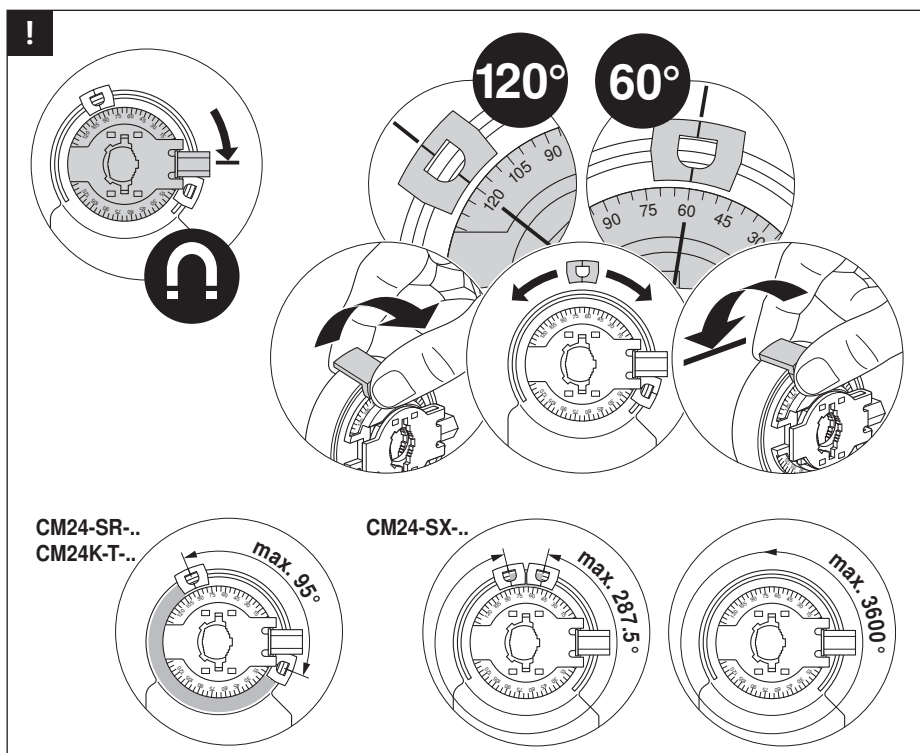
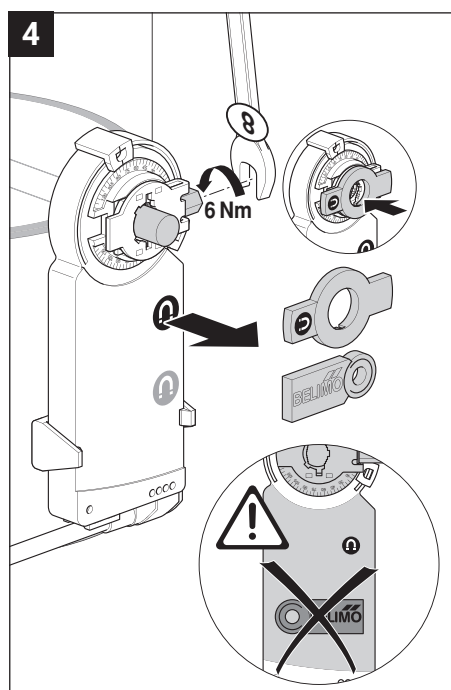
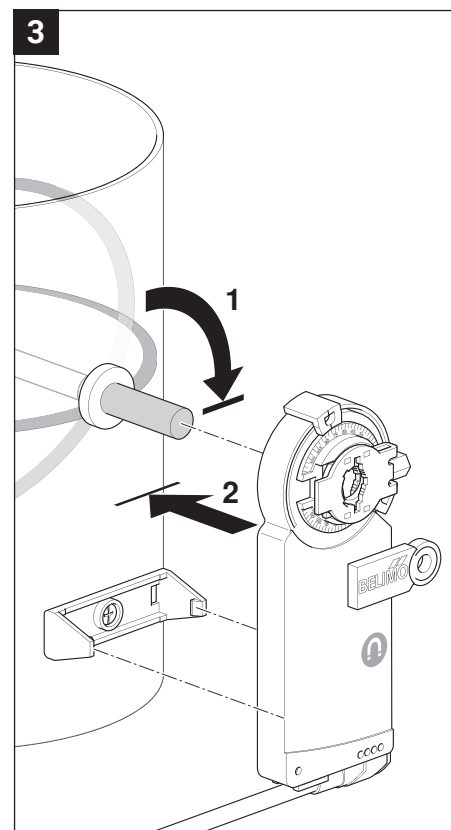
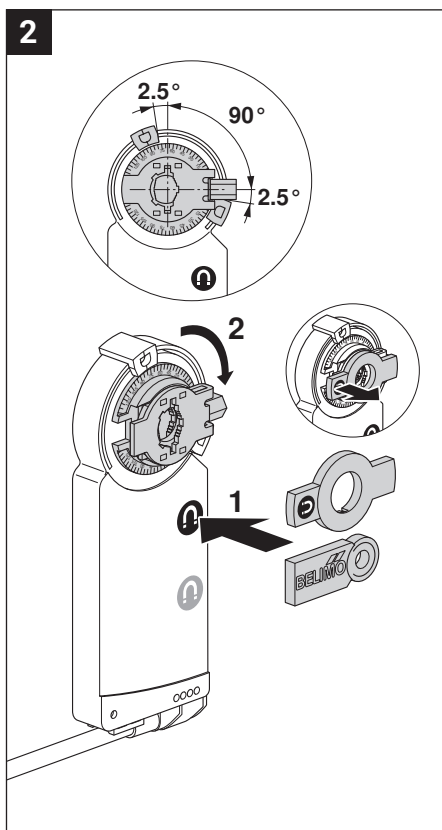
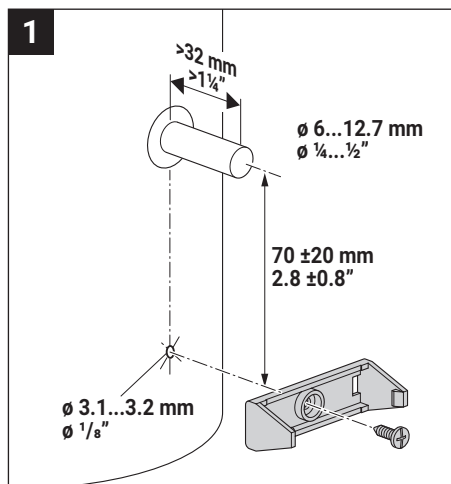
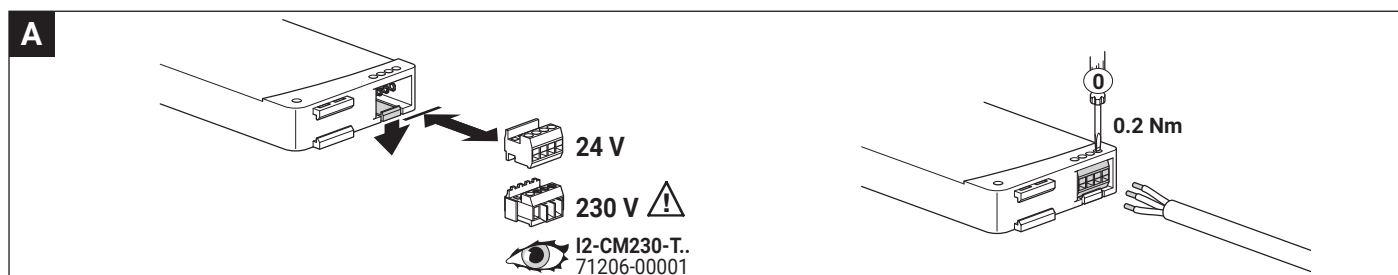
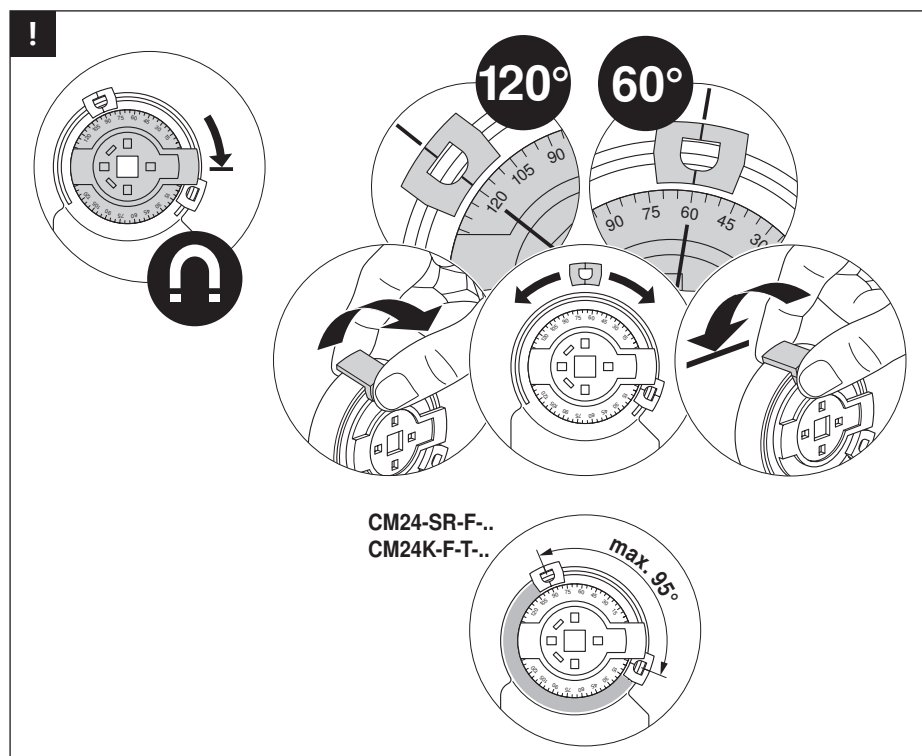
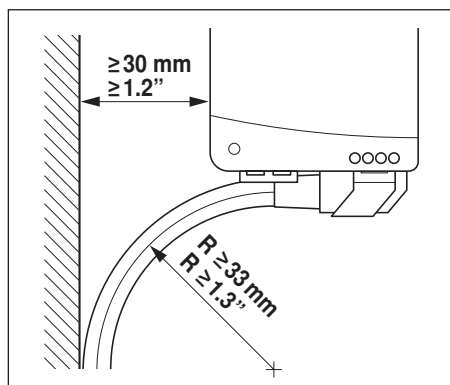
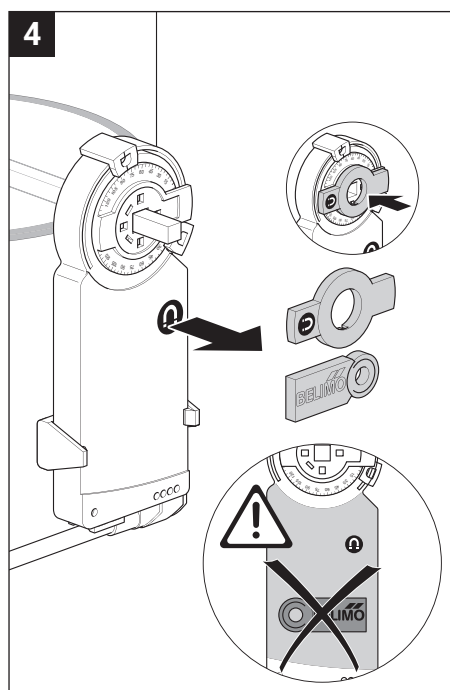
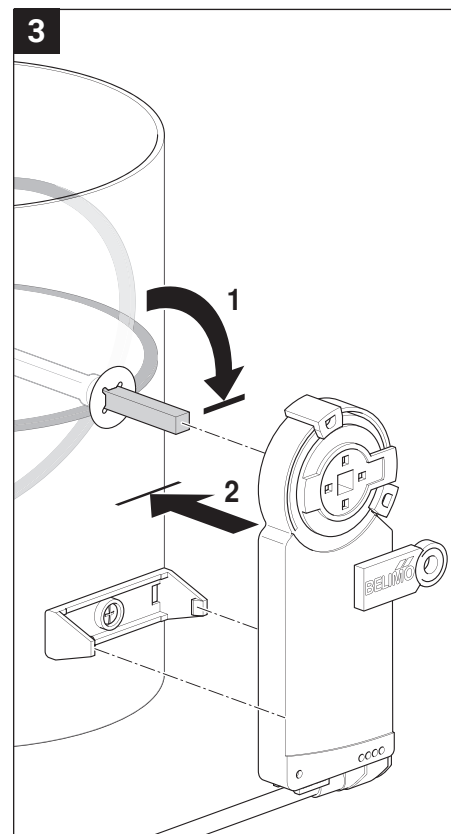


 
CM24-.. / CM24-T-.. / CM230-.. / CM24-SR-.. / CM24-SR-T-.. / CM24K-T-.. / CM24-SX-..

70728-00001.C




 

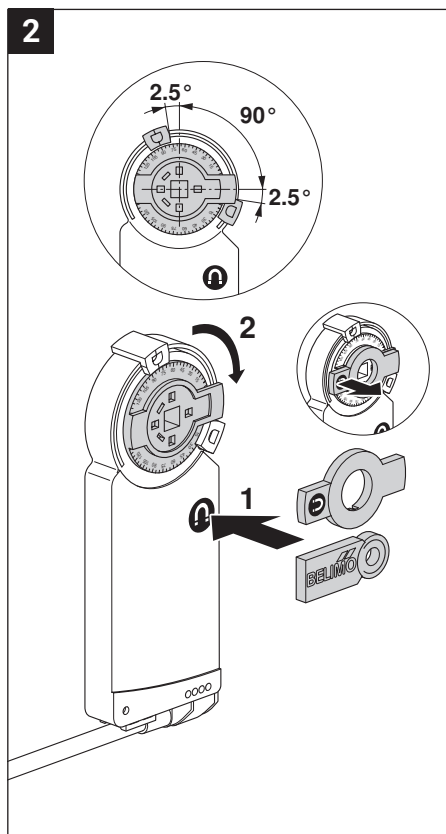



CM24-F-.. / CM24-F-T-.. / CM230-F-.. / CM24-SR-F-.. / CM24-SR-F-T-.. / CM24K-F-T-..

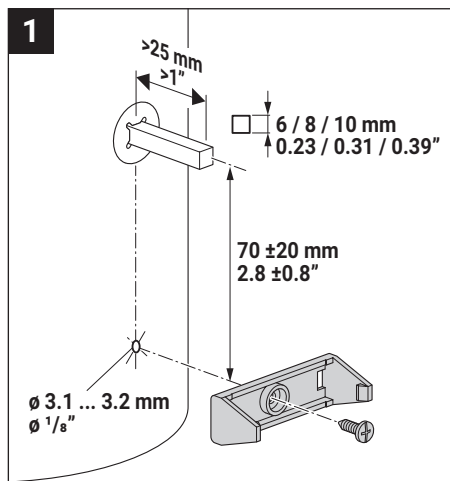



AC 24 V / DC 24 V

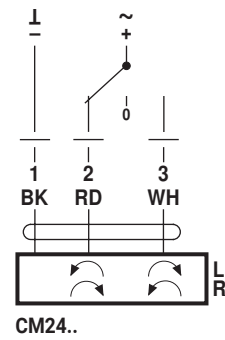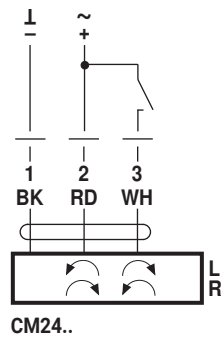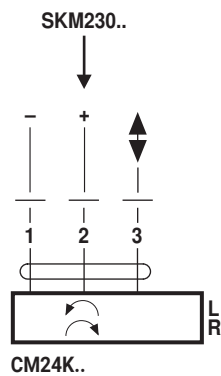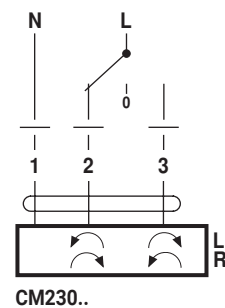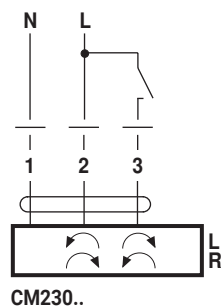DC 24 V
(SKM230..)AC 100 ... 240 V 

AC 24 V / DC 24 V

