




5

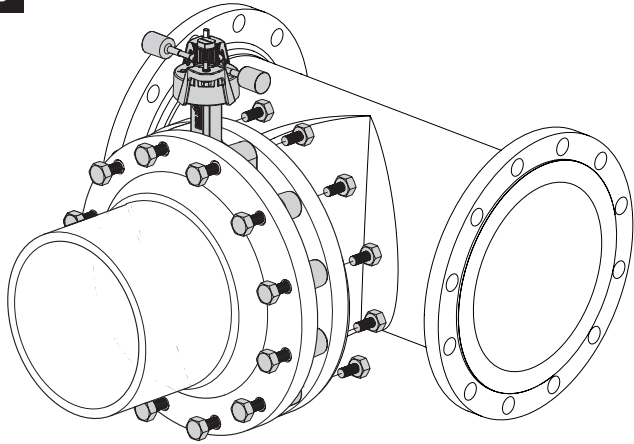


6

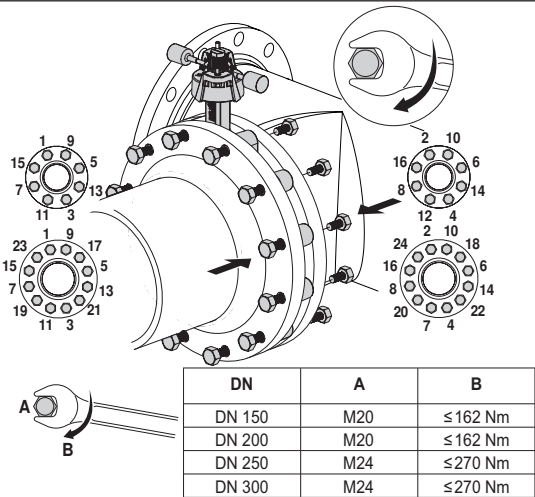


6i

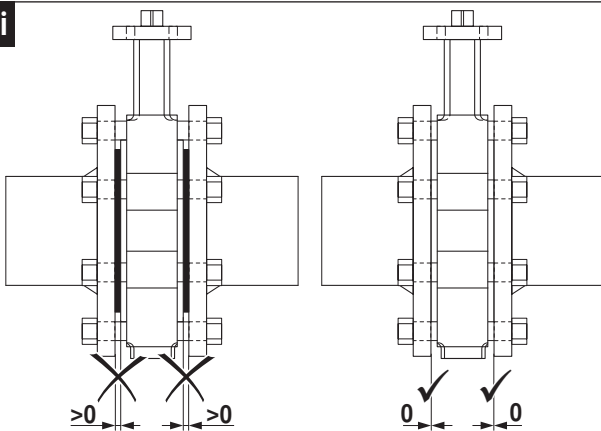


i

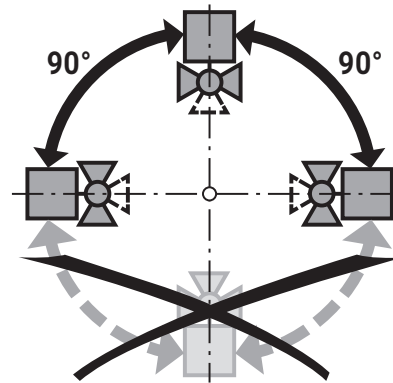


i

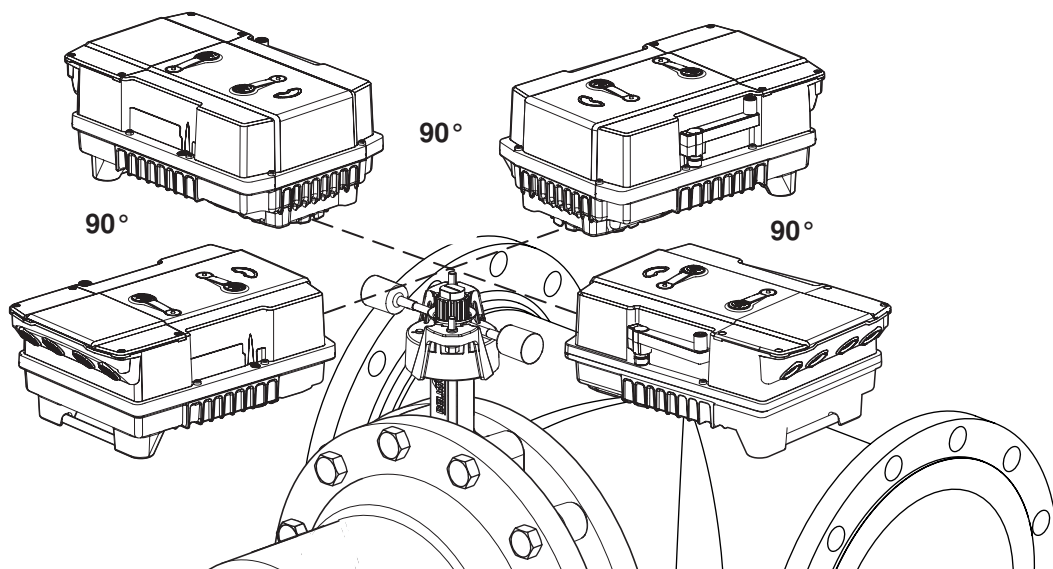


7

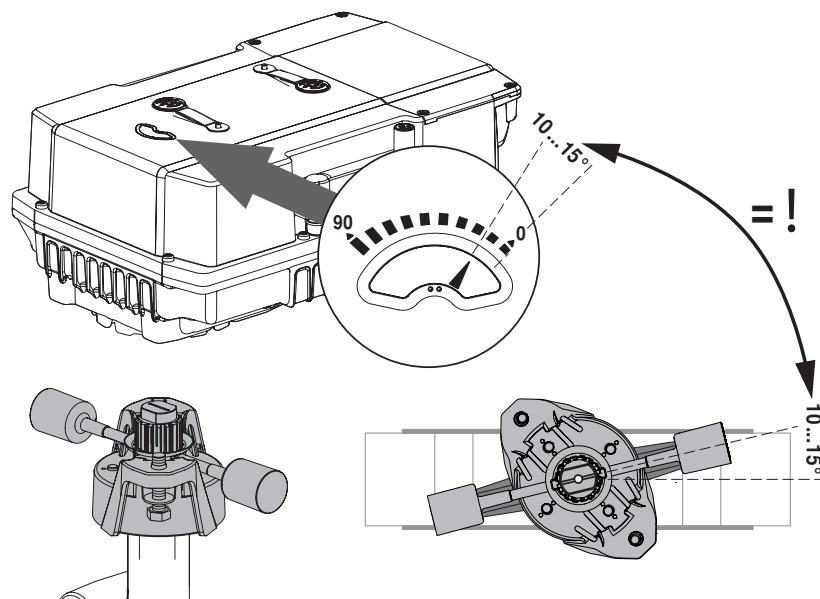


8

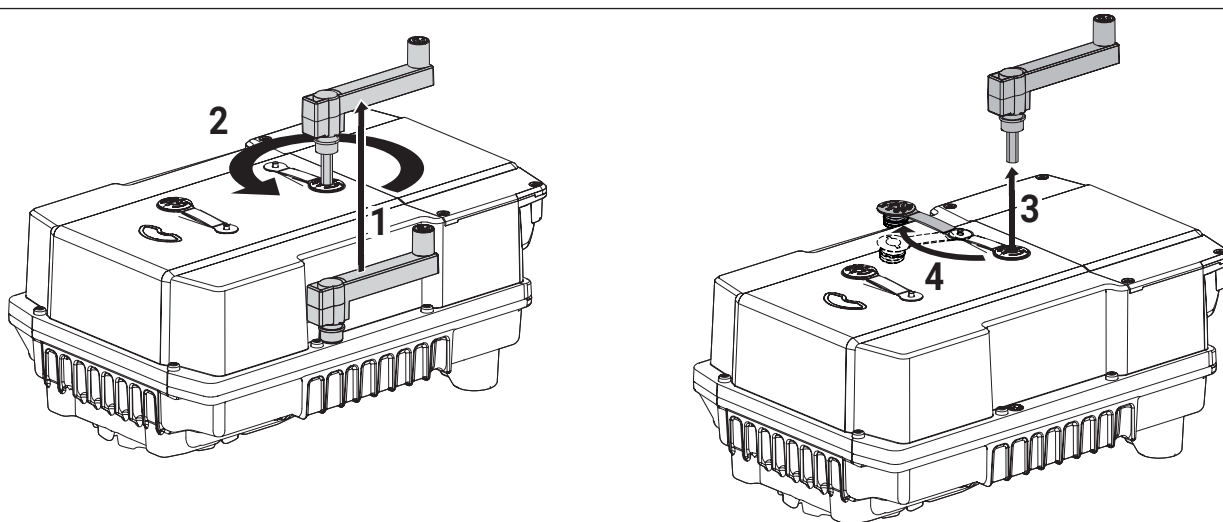


9

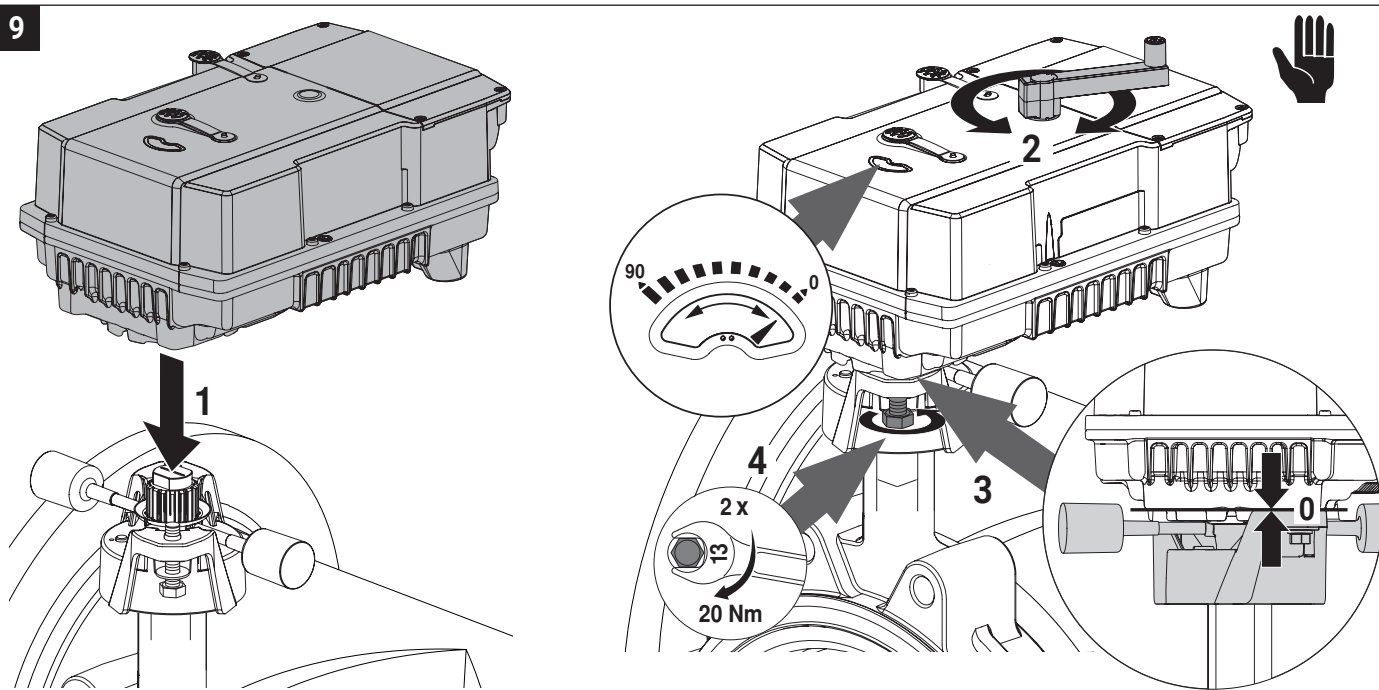


10

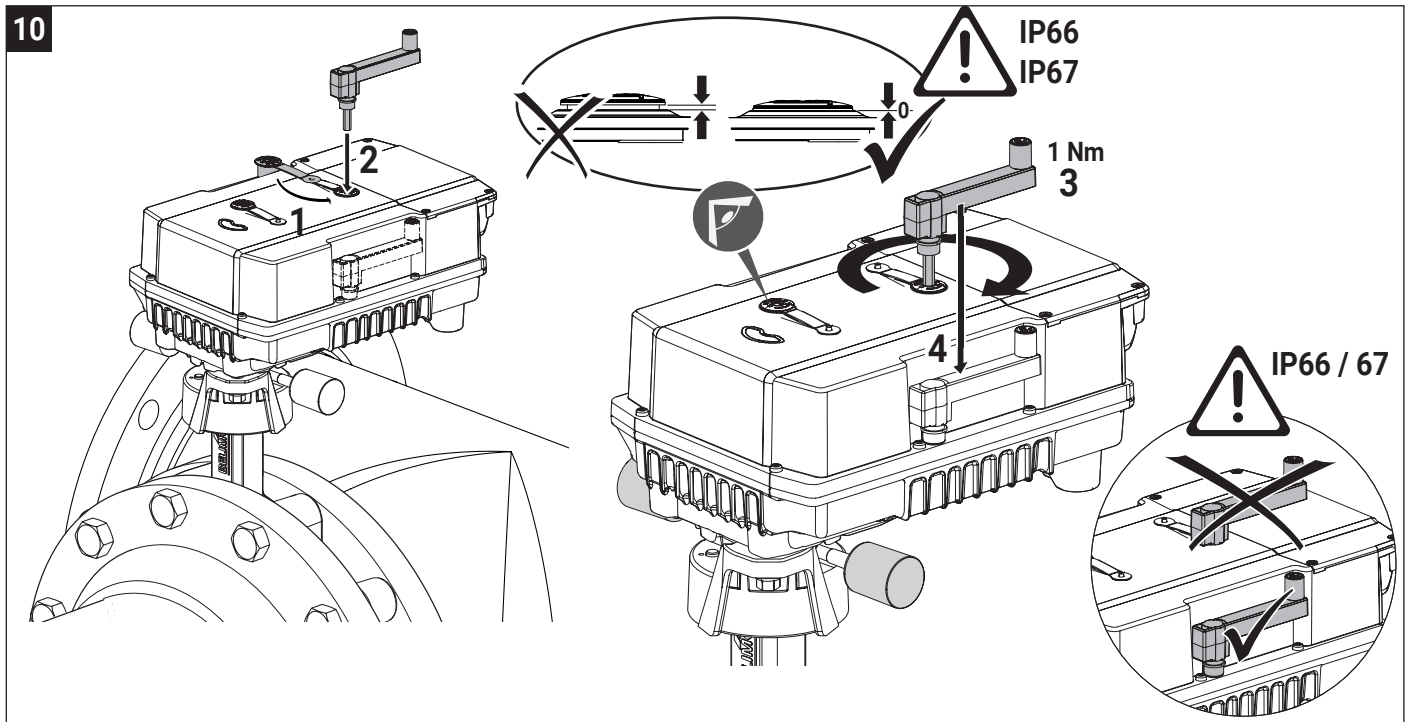



11





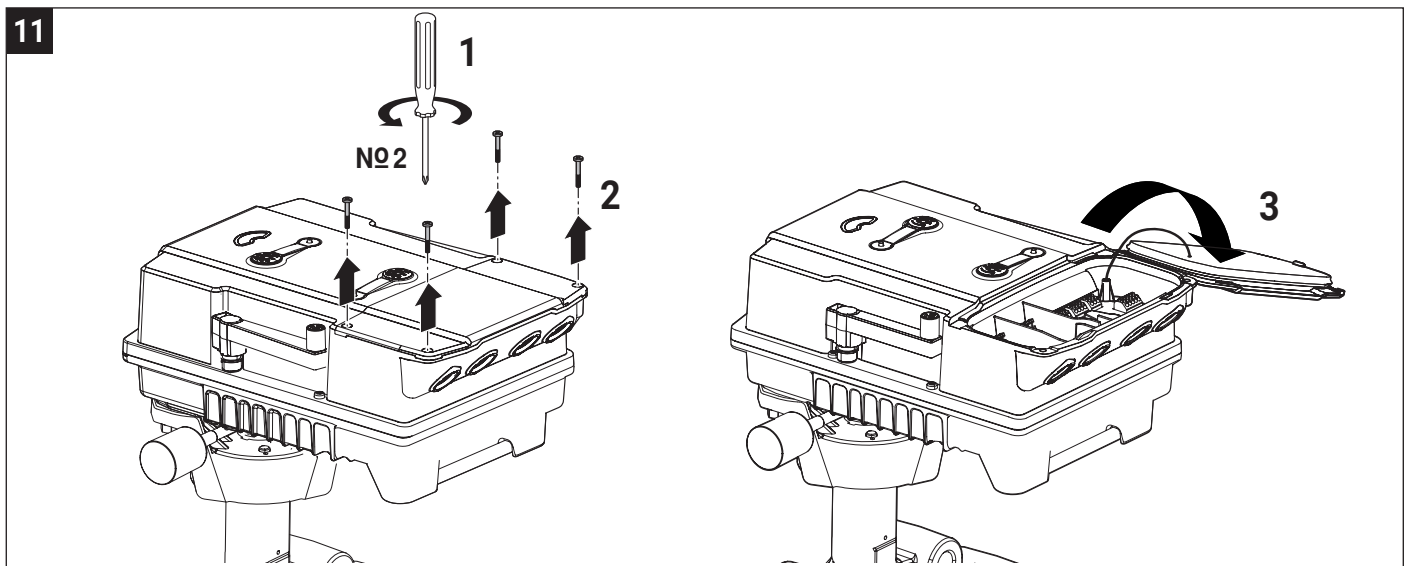


12

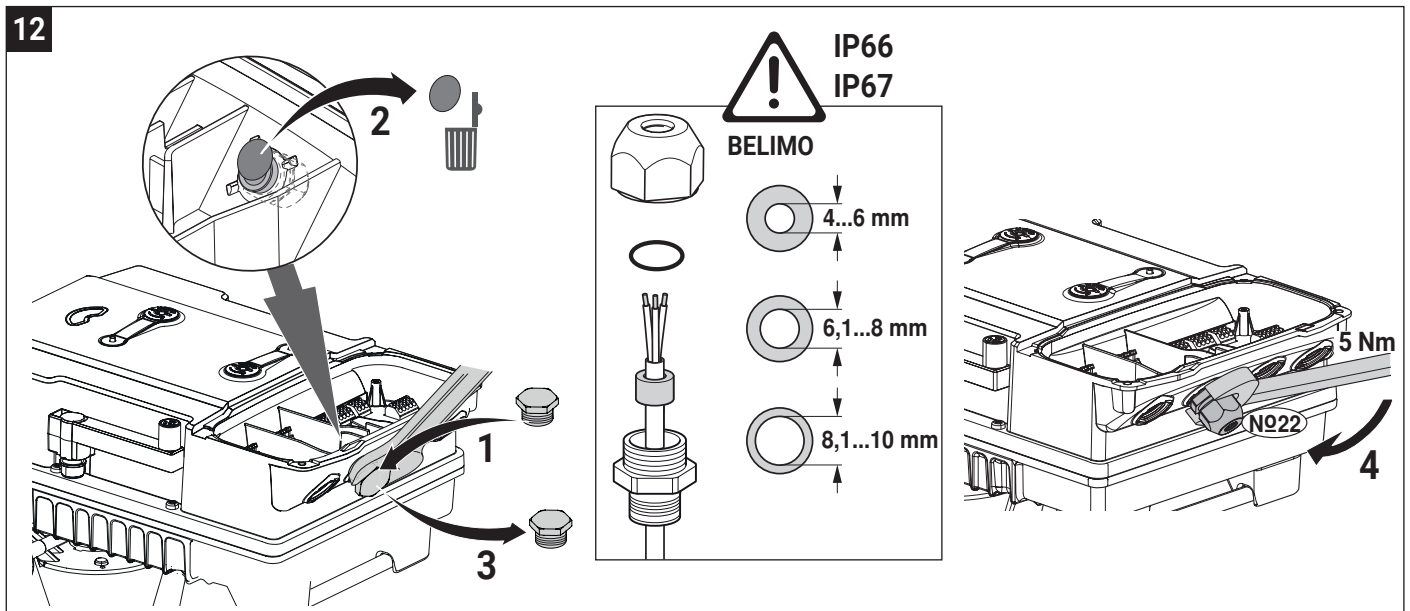


13

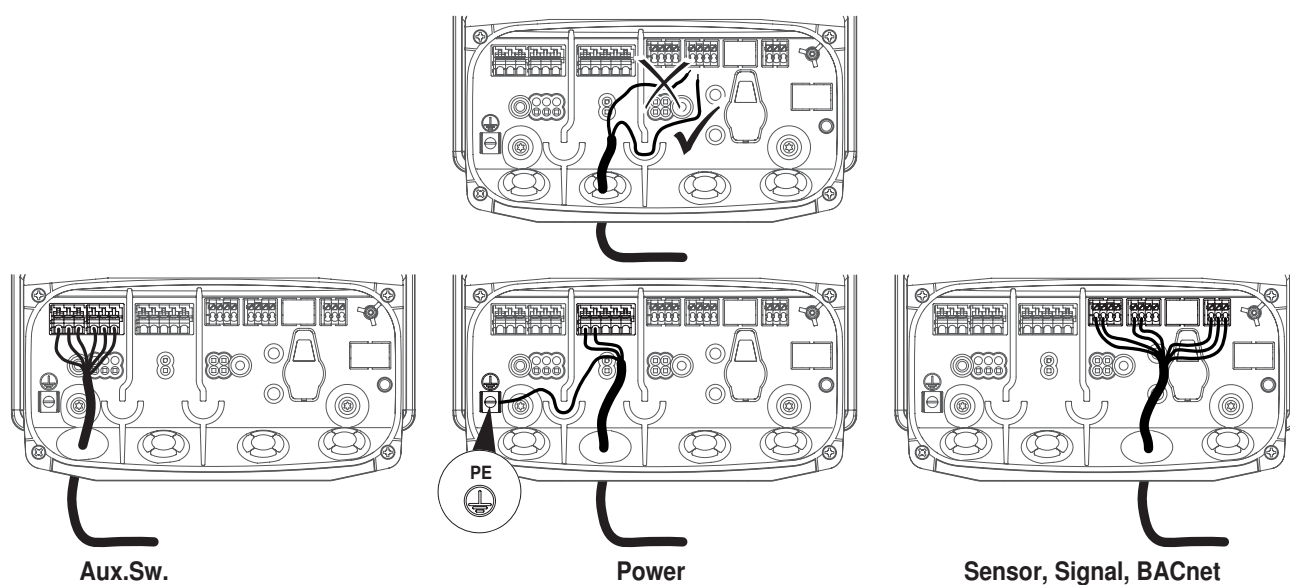
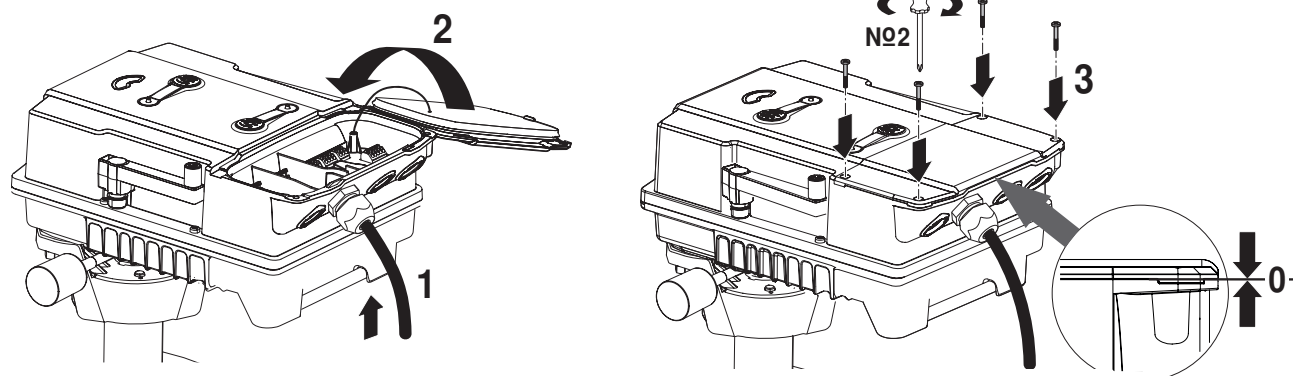


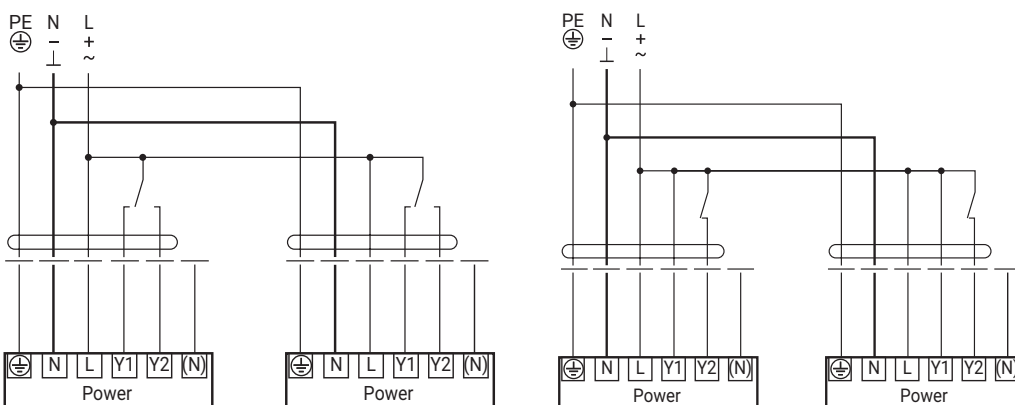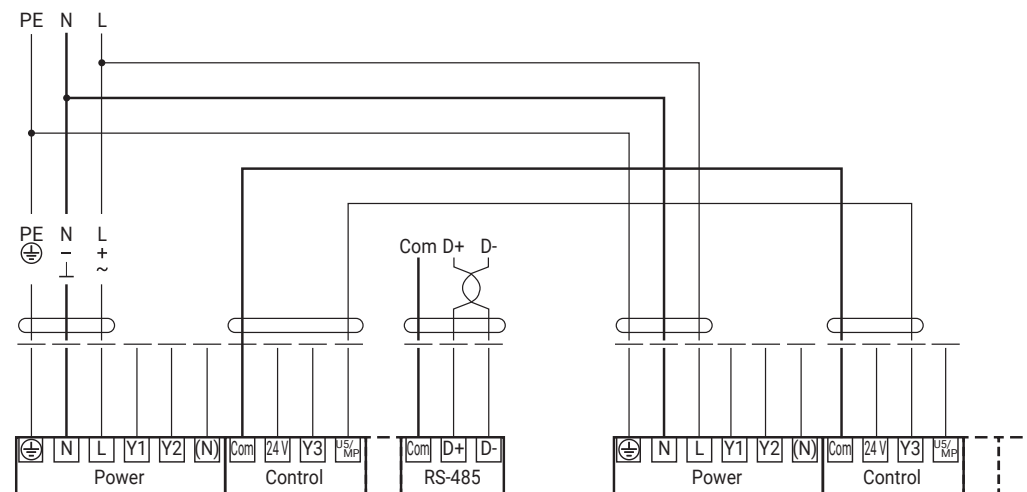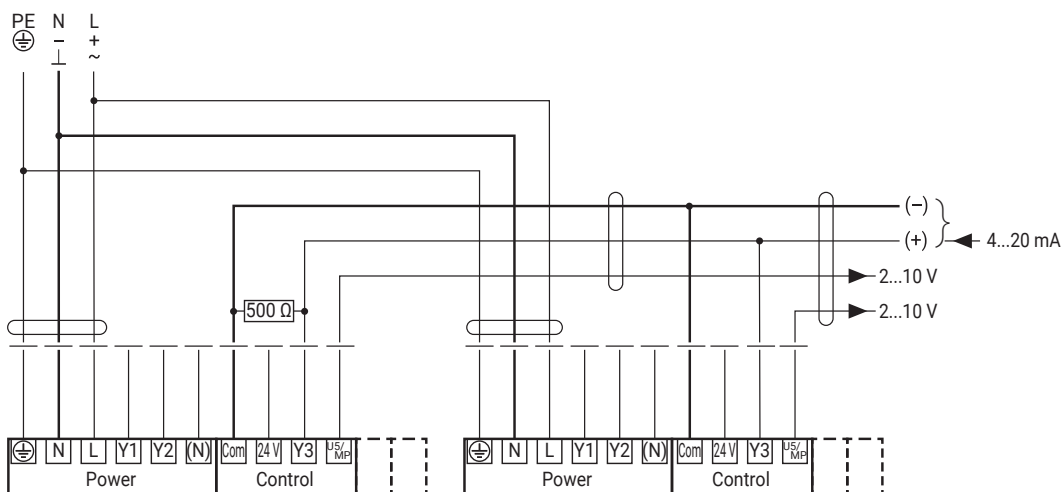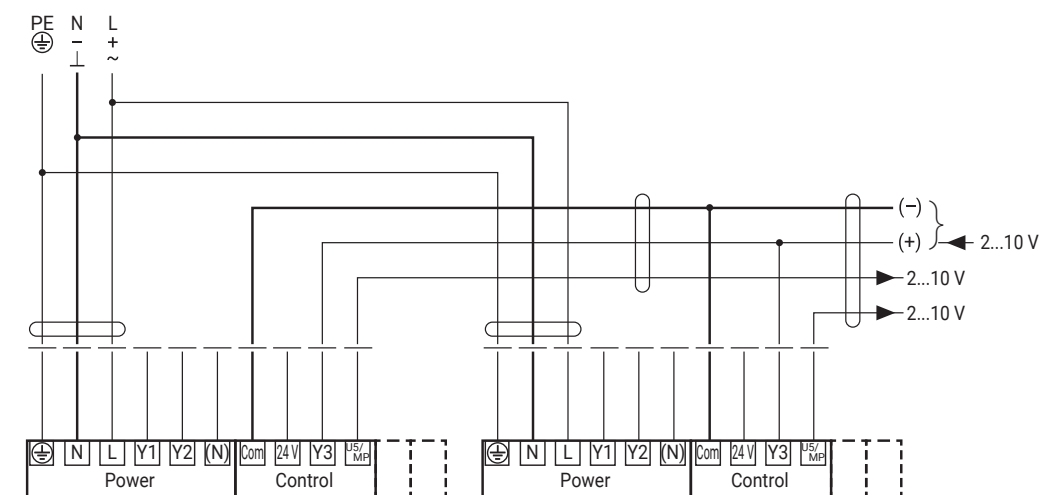 

i

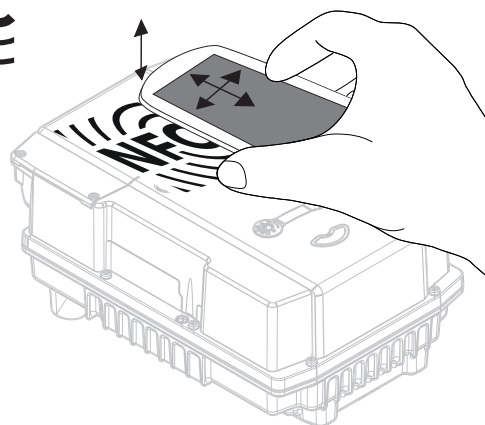i

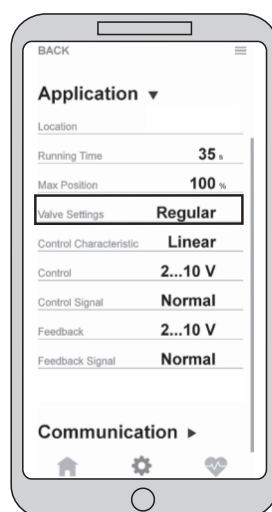
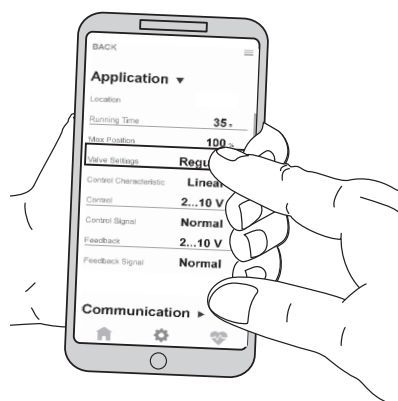


Regular	DN 80...150 D6300W(L) Retrofit
DN 200/8"	D6200W(L)
DN 250/10"	D6250W(L)



max. flow velocity
4 m/s

i

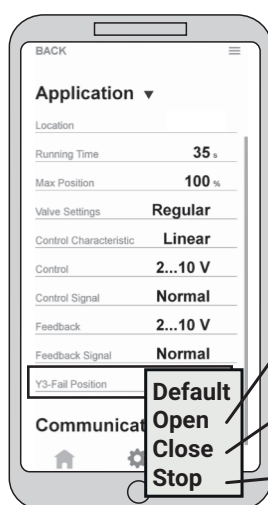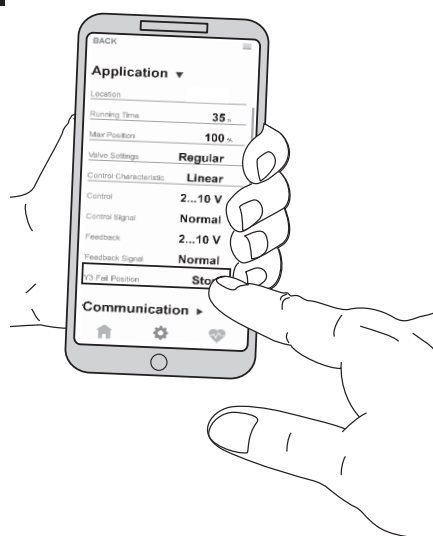

Y3-Fail
Position

Control Signal
Normal

Control Signal
Inverted

A-AB
Default



A-AB
100 %




A-AB
0 %




A-AB
STOP



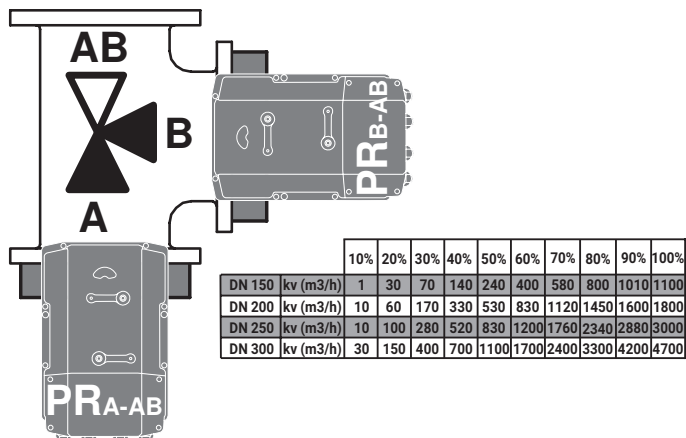

D7..L/BAC

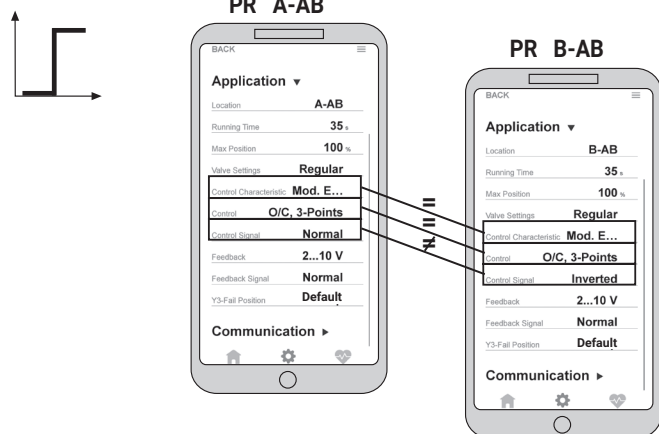

D7..L/BAC

