


71665-00001.A Schneider-Electric / TAC

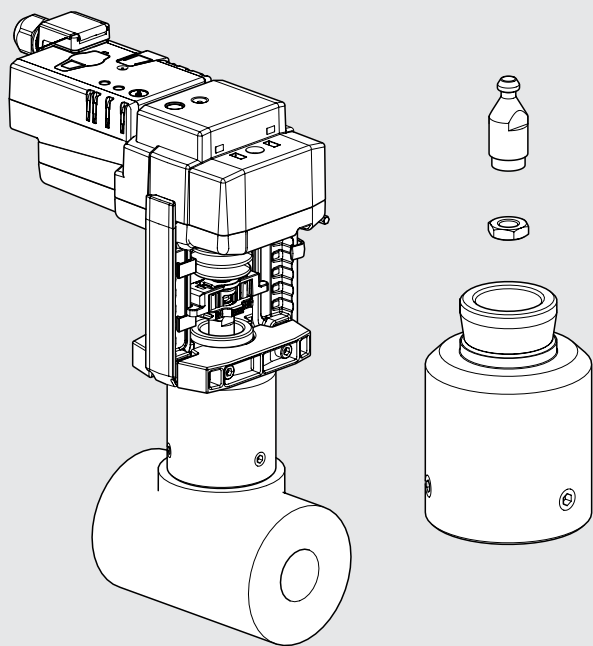

	Schneider-Electric / TAC	DN min. / max.	t
	V231	15 / 50	2 ... 150 °C
	V241	15 / 50	2 ... 150 °C
	V294	15 / 32	2 ... 150 °C
	V341	15 / 50	2 ... 150 °C
	V348	15 / 50	2 ... 150 °C
	V353	15 / 50	2 ... 150 °C
	V384	20 / 32	2 ... 150 °C
	V386	20 / 32	2 ... 150 °C
	V392	20 / 32	2 ... 150 °C
	V394	20 / 32	2 ... 150 °C

